



## Main

Range of product	Harmony Relay
Product or component type	Socket
Contact terminal arrangement	Separate

## Complementary

Product compatibility	Plug-in relay RXG 2 C/O
[Ui] rated insulation voltage	250 V
[Uimp] rated impulse withstand voltage	6 kV
Line Rated Current	5 A
[Ue] rated operational voltage	250 V IEC 300 V UL
Connections - terminals	Screw terminals, 1 x 0.25...1 x 2.5 mm <sup>2</sup> AWG 22...AWG 14) flexible with cable end Screw terminals, 2 x 0.25...2 x 1 mm <sup>2</sup> AWG 22...AWG 17) flexible with cable end Screw terminals, 2 x 0.5...2 x 1.5 mm <sup>2</sup> AWG 20...AWG 16) solid without cable end Screw terminals, 1 x 0.5...1 x 2.5 mm <sup>2</sup> AWG 20...AWG 14) solid without cable end
Screw type	M3

## Environment

Ambient air temperature for storage	-40...185 °F (-40...85 °C)
Ambient air temperature for operation	-40...158 °F (-40...70 °C)
Relative humidity	10...85 %
Standards	CSA C22.2 No 14 IEC 61984 UL 508
Product certifications	RoHS EAC CE

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

CSA  
China RoHS  
UL  
REACH

IP degree of protection	IP20
Overvoltage category	III
Pollution degree	3

### Ordering and shipping details

Category	21128 - ZELIO ICE CUBE RELAY ACCESSORIES
Discount Schedule	CP2
GTIN	00785901432128
Nbr. of units in pkg.	10
Package weight(Lbs)	0.09 lb(US) (0.04 kg)
Returnability	Yes
Country of origin	CN


### Packing Units

Package 1 Height	2.44 in (62.000 mm)
Package 1 width	0.62 in (15.800 mm)
Package 1 Length	3.03 in (77.000 mm)

### Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Dimensions

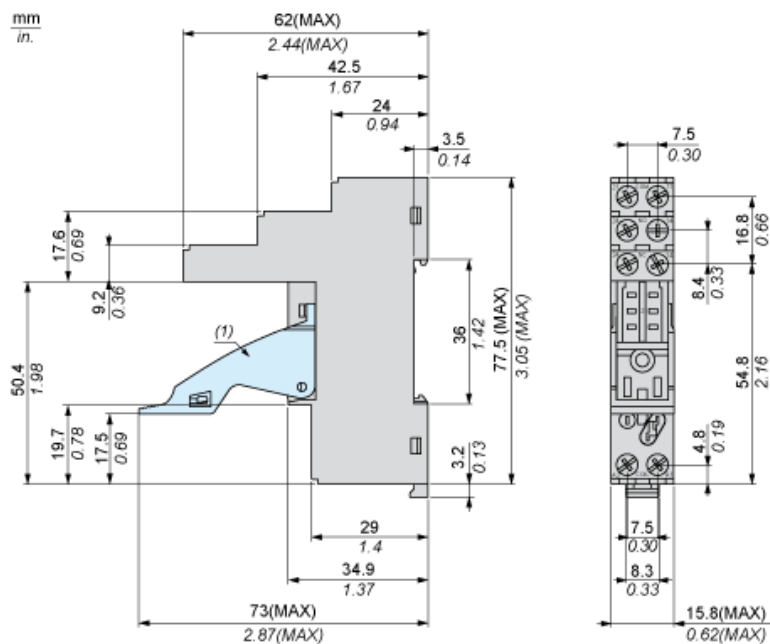

(1) Maintaining clamp

Wiring Diagram

