



Main

| | |
|-------------------------------|---------------------------|
| Range of product | Zelio Relay |
| Product or component type | Socket |
| Contact terminal arrangement | Mixed |
| Product compatibility | Plug-in relay RPM (4 C/O) |
| Shape of pin | Flat |
| Device short name | RPZ |
| Sale per indivisible quantity | 10 |

Complementary

| | |
|--|--|
| [I _{th}] conventional free air thermal current | 15 A |
| [U _e] rated operational voltage | < 250 V |
| Tightening torque | < 1 N.m (M3.5 screw(s)) |
| Fixing mode | By screw mounting on panel Clip-on mounting on 35 mm symmetrical DIN rail |
| Marking | CE |
| Width | 50 mm |
| Product weight | 0.094 kg |
| Group of product | RPM_4_C/O_SC_TER_MIX_FLAT |
| Compatibility code | RPZ |


Environment

| | |
|---------------------------------------|---|
| Connections - terminals | - screw clamp terminals, flexible cable with cable end 1 x 0.25...2 x 1 mm ² / AWG 22...AWG 17 - screw clamp terminals, solid cable without cable end 1 x 0.5...2 x 1.5 mm ² / AWG 20...AWG 16 |
| Standards | IEC 61984 |
| Product certifications | CSA UL |
| Ambient air temperature for storage | -40...85 °C |
| Ambient air temperature for operation | -40...55 °C |
| IP degree of protection | IP20 conforming to EN/IEC 60529 |
| Dielectric strength | 2500 V |

Contractual warranty

| | |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

Wiring Diagram

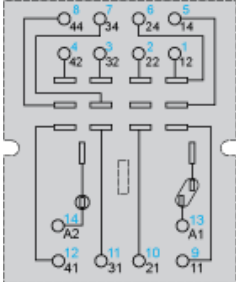

Symbols shown in blue correspond to Nema marking.