



Main

Range of product	Zelio Relay
Product or component type	Socket
Contact terminal arrangement	Separate
Product compatibility	Plug-in relay RSB (1 C/O) Plug-in relay RSB (2 C/O)
Shape of pin	Flat
Device short name	RSZ
Sale per indivisible quantity	10

Complementary

[I _{th}] conventional free air thermal current	10 A
[U _e] rated operational voltage	< 250 V AC
Tightening torque	< 0.8 N.m (M3 screw(s))
Fixing mode	By screw mounting on panel Clip-on mounting on 35 mm symmetrical DIN rail
Marking	CE
Width	15.5 mm
Product weight	0.05 kg

Environment


Connections - terminals	Screw connectors, flexible cable with cable end 1 x 0.25...1 x 2.5 mm ² / AWG 22...AWG 14 Screw connectors, flexible cable with cable end 2 x 0.25...2 x 1 mm ² / AWG 22...AWG 17 Screw connectors, solid cable without cable end 1 x 0.5...1 x 2.5 mm ² / AWG 20...AWG 14 Screw connectors, solid cable without cable end 2 x 0.5...2 x 1.5 mm ² / AWG 20...AWG 16
Standards	IEC 61984
Product certifications	UL CSA
Ambient air temperature for storage	-40...85 °C
Ambient air temperature for operation	-25...85 °C
IP degree of protection	IP20 conforming to EN/IEC 60529
Dielectric strength	2500 V

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Contractual warranty

Warranty period	18 months
-----------------	-----------

Wiring Diagram

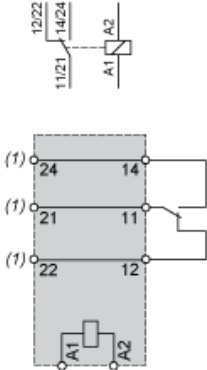

(1) Before wiring please refer to the Instruction sheet