


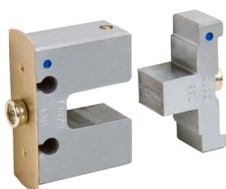

PRODUCT-DETAILS

13671A**12TON DIE CRIMPING 204 DRAGON TERM****General Information**

Extended Product Type:	13671A
Product ID:	7TAA131850R0032
EAN:	5414363111320
Catalog Description:	12TON DIE CRIMPING 204 DRAGON TERM
Long Description:	Die for 12 Ton 13400 or 13642M Hydraulic Tool for Crimping 204 Series Dragon Tooth Terminals
Display Name:	13671A

Ordering

EAN:	5414363111320
UPC:	786210871028
Country of Origin:	United States
Selling Unit of Measure:	each

Container Information

Package Level 1 Units:	1 EA
Package Level 1 Width:	127 mm 5 in
Package Level 1 Height:	31.75 mm 1.25 in
Package Level 1 Depth / Length:	127 mm 5 in
Package Level 2 Units:	100 EA
Package Level 2 Width:	0 mm 0 in
Package Level 2 Height:	0 mm 0 in
Package Level 2 Depth / Length:	0 mm 0 in

Additional Information

Application:	Crimping Dragon Tooth terminal for magnet wire.
Brand / Label:	Application Tooling
Color:	Silver
Effective Date:	19720606
Material:	Alloy Steel
Product Name:	Metal forming dies, including thread-rolling dies
Product Type:	Die

External Classifications and Standards

ETIM 7:	EC001282 - Insert for crimp tool cable lugs, cable end sleeves, screen connection
ETIM 8:	EC001282 - Insert for crimp tool cable lugs, cable end sleeves, screen connection
ETIM 9:	EC001282 - Insert for crimp tool cable lugs, cable end sleeves, screen connection
ETIM 10:	EC001282 - Insert for crimp tool cable lugs, cable end sleeves, screen connection
UNSPSC:	27112820
IDEA Granular Category Code (IGCC):	2427 >> Lug crimping tool dies

Material Compliance

RoHS Information:	Following EU Directive 2011/65/EU and Amendment 2015/863 July 22, 2019
REACH Information:	False - does not contain substances > 0.1 mass percentage
WEEE Category:	Product Not in WEEE Scope
Conflict Minerals Reporting Template (CMRT):	9AKK108472A2584

Categories

Products > Low Voltage Products and Systems > Installation Products > Wire Management and Connectivity > WMC Tools > Connector Tools

