
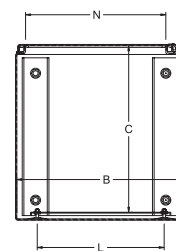
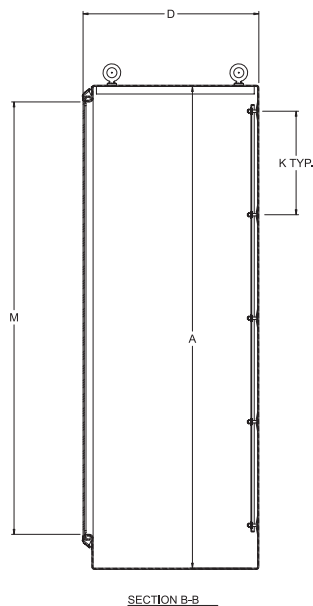


## Control Enclosures - ControlTower® Single Door, Free Standing

### N ControlTower® Single Door, Free Standing



FS	Type 12, SS hinged, latched down cover
FSHWT	Type 4X, SS hinged, latched down cover
FSFHLWT	Type 4X, fiberglass hinged, through the door latches
FSRT	Type 3R, SS hinged, latched down cover

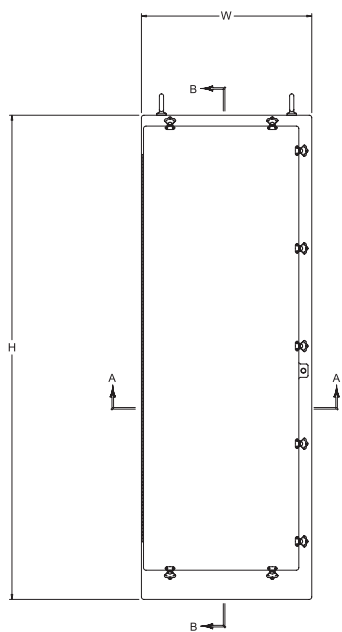


# Control Enclosures - ControlTower® Double Door, Wall Mounted

## N ControlTower® Double Door, Wall Mounted

DDHWT Type 4X, SS hinged, latched down cover  
 DDRT Type 3R, SS hinged, latched down cover

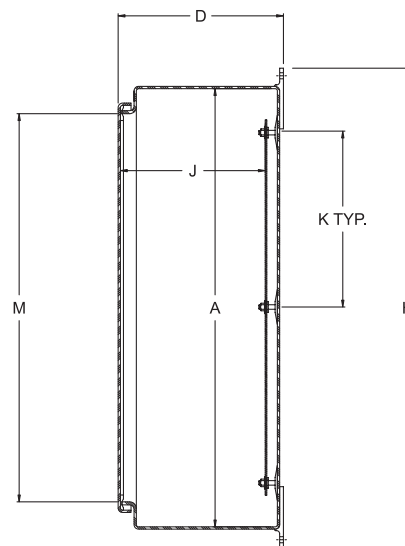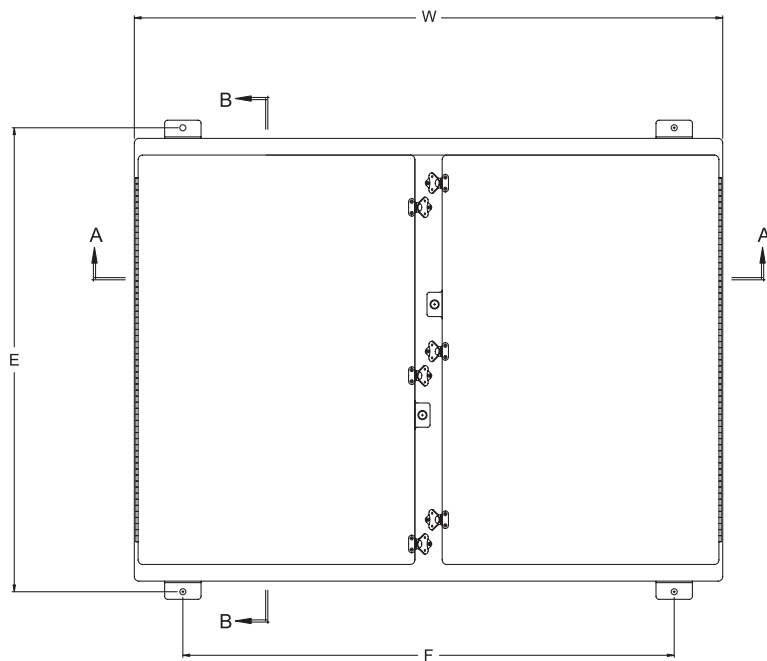

SECTION B-B



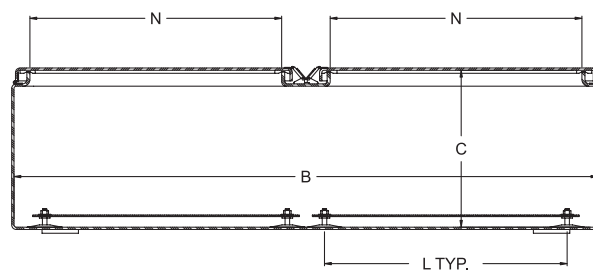


SECTION A-A

# Control Enclosures - ControlTower® Double Door, Free Standing

## N ControlTower® Double Door, Free Standing

- FSDD Type 12, SS hinged, latched down cover
- FSDDHWT Type 4X, SS hinged, latched down cover
- FSDDFHLWT Type 4X, fiberglass hinged, through the door latches
- FSDDRT Type 3R, SS hinged, latched down cover

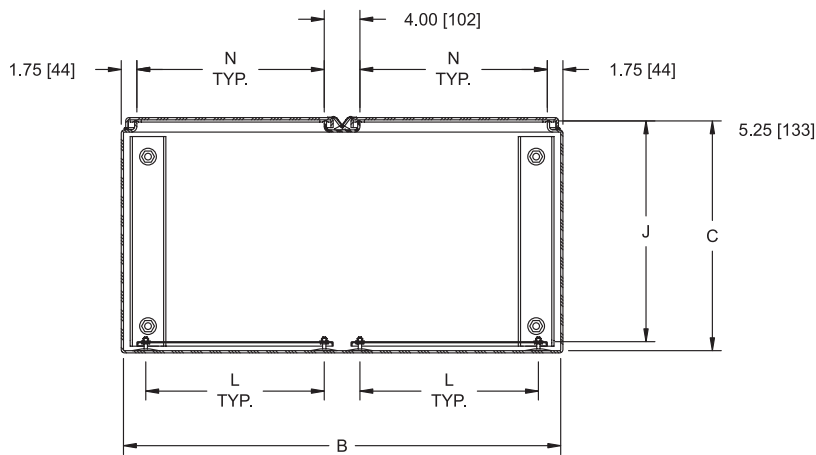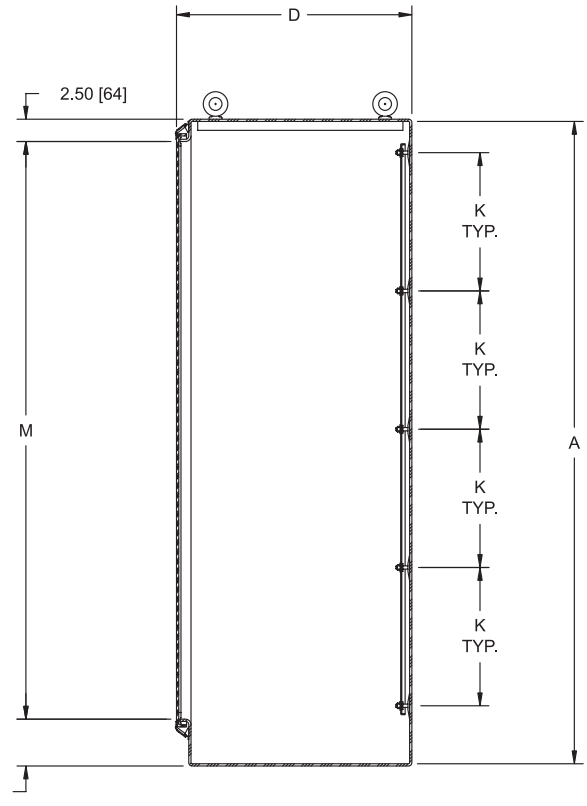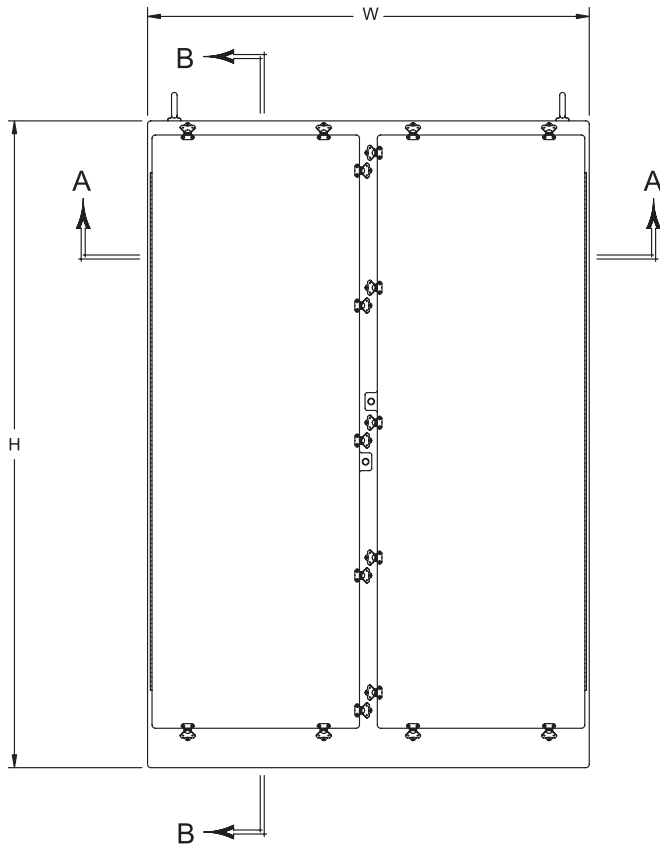

## Control Enclosures Configuration Technical Charts

### Control Tower Enclosures Dimensions

SIZE ID NUMBER	OVERALL H X W X D	INSIDE A X B X C	MOUNTING E X F	J	K	L	ENCLOSURE OPENING M X N	NO. OF LATCHES	SHIPPING WEIGHT	PANEL NUMBER
N364812DDRT N364812DDFHLWT	39.50 x 48.50 x 13.62 (1003 x 1232 x 346)	36.12 x 48.12 x 13.00 (917 x 1222 x 330)	38.25 x 40.5 (972 x 1029)	11.94 (303)	14.50 (368)	20.00 (508)	32.00 x 20.75 (813 x 527)	6 14	140 lbs.	BP3648 (2)**
N483612RT N483612FHLWT N483612HWT N483612*	51.29 x 36.62 x 13.93 (1303 x 930 x 354)	48.33 x 36.22 x 13.25 (1228 x 920 x 336)	50.12 x 28.50 (1273 x 724)	12.25 (311)	21.63 (549)	31.25 (794)	45.25 x 32.00 (1149 x 813)	3 10 10 3	96 lbs.	BP4836**
N483616RT N483616FHLWT N483616HWT N483616*	51.29 x 36.62 x 17.93 (1303 x 930 x 456)	48.33 x 32.22 x 17.25 (1228 x 920 x 438)	50.12 x 28.50 (1273 x 724)	16.25 (413)	21.63 (549)	31.25 (794)	45.25 x 32.00 (1149 x 813)	3 10 10 3	109 lbs.	BP4836**
N54428DDRT	57.50 x 42.50 x 9.62 (1460 x 1080 x 244)	54.12 x 42.12 x 9.00 (1374 x 1069 x 228)	56.25 x 34.50 (1429 x 876)	7.94 (201)	23.50 (596)	17.00 (431)	50.00 x 17.50 (1270 x 444)	8	162 lbs.	BP5442 (2)**
N602418RT N602418HWT	63.75 x 24.50 x 20.12 (1619 x 622 x 511)	60.38 x 36.13 x 19.44 (1533 x 918 x 493)	62.50 x 16.75 (1587 x 425)	18.44 (468)	27.63 (702)	19.25 (489)	57.25 x 20.00 (1454 x 508)	9	175 lbs.	BP6024**
N603612RT N603612FHLWT N603612HWT N603612*	64.00 x 36.50 x 14.12 (1627 x 927 x 359)	60.62 x 36.13 x 13.44 (1540 x 918 x 441)	62.75 x 28.75 (1594 x 730)	12.44 (316)	27.63 (702)	31.25 (794)	57.25 x 32.00 (1454 x 813)	3 11 11 3	125 lbs.	BP6036**
N603616RT N603616FHLWT N603616HWT N603616*	64.00 x 36.50 x 18.12 (1627 x 927 x 460)	60.62 x 36.13 x 17.44 (1540 x 918 x 443)	62.75 x 28.75 (1594 x 730)	16.44 (418)	27.63 (702)	31.25 (794)	57.25 x 32.00 (1454 x 813)	3 11 11 3	130 lbs.	BP6036**
N603624HWT	63.75 x 36.50 x 26.12 (1619 x 927 x 663)	60.38 x 36.13 x 25.44 (1533 x 918 x 646)	62.50 x 28.75 (1587 x 730)	24.44 (621)	27.63 (702)	31.25 (794)	57.25 x 32.00 (1454 x 813)	11	140 lbs.	BP6036**
N606012FSDDRT	60.50 x 60.50 x 13.38 (1537 x 1537 x 340)	60.13 x 60.13 x 13.01 (1524 x 1524 x 324)	NA	11.88 (298)	13.00 (330)	25.50 (648)	52.75 x 26.50 (1340 x 673)	10	285 lbs.	BP6060**
N722418FSRT N722418FSHWT	72.50 x 24.50 x 19.38 (1841 x 610 x 492)	72.00 x 24.00 x 18.88 (1829 x 610 x 479)	NA	17.88 (454)	15.50 (388)	18.00 (457)	64.75 x 20.00 (1645 x 508)	5 9	158 lbs.	BP7224**
N722525FSRT N722525FSFHLWT N722525FSHWT N722525FS*	72.50 x 25.50 x 26.38 (1841 x 648 x 670)	72.00 x 25.00 x 25.88 (1829 x 635 x 657)	NA	24.88 (632)	15.50 (388)	19.00 (483)	64.75 x 21.00 (1645 x 533)	5 9 9 5	230 lbs.	BP7225**
N723618FSFHLWT	72.50 x 36.50 x 19.38 (1841 x 927 x 492)	72.00 x 36.00 x 18.88 (1829 x 914 x 479)	NA	17.88 (454)	15.50 (388)	30.00 (762)	64.75 x 32.00 (1645 x 813)	11	290 lbs.	BP7236**
N724818FSDD*	72.50 x 48.50 x 19.38 (1842 x 1232 x 492)	72.00 x 48.00 x 18.88 (1824 x 1219 x 476)	NA	17.88 (450)	15.50 (394)	19.50 (495)	64.75 x 20.50 (1645 x 521)	10	300 lbs.	BP7248**
N724925FSDDRT N724925FSDD*	72.50 x 49.50 x 26.38 (1842 x 1257 x 670)	72.00 x 49.00 x 25.88 (1829 x 1245 x 654)	NA	24.88 (628)	15.50 (394)	20.00 (508)	64.75 x 21.00 (1645 x 533)	10	520 lbs.	BP7249**
N726012FSDD*	72.50 x 60.50 x 13.38 (1842 x 1537 x 340)	72.00 x 60.00 x 12.88 (1829 x 1524 x 324)	NA	11.88 (298)	15.50 (394)	25.50 (648)	64.75 x 26.50 (1645 x 673)	10	315 lbs.	BP7260**
N726018FSDD*	72.50 x 60.50 x 19.38 (1842 x 1537 x 492)	72.00 x 60.00 x 18.88 (1829 x 1524 x 476)	NA	17.88 (450)	15.50 (394)	25.50 (648)	64.75 x 26.50 (1645 x 673)	10	375 lbs.	BP7260**
N727212FSDDFHLWT	72.50 x 72.50 x 13.38 (1842 x 1842 x 340)	72.00 x 72.00 x 12.88 (1829 x 1829 x 324)	NA	11.88 (298)	15.50 (394)	31.50 (800)	64.75 x 32.50 (1645 x 826)	22	480 lbs.	BP7272**
N727218FSDDRT	72.50 x 72.50 x 19.38 (1842 x 1842 x 492)	72.00 x 72.00 x 18.88 (1829 x 1829 x 425)	NA	17.88 (400)	15.50 (394)	31.50 (800)	64.75 x 32.50 (1645 x 826)	10	557 lbs.	BP7272**
N727220FSDDFHLWT	72.50 x 72.50 x 21.38 (1842 x 1842 x 543)	72.00 x 72.00 x 20.88 (1829 x 1829 x 527)	NA	19.88 (501)	15.50 (394)	31.50 (800)	64.75 x 32.50 (1645 x 826)	22	430 lbs.	BP7272**
N903620FSRT	90.50 x 36.50 x 21.38 (2299 x 927 x 543)	90.00 x 36.00 x 20.88 (2286 x 914 x 530)	NA	19.88 (505)	20.00 (508)	30.00 (762)	82.75 x 32.00 (2102 x 813)	6	307 lbs.	BP9036**

\*Available as made to order.

All measures are in inches, items in parentheses are in millimeters.

NOTE: Mounting hole dimension is .50 inches.

\*\*Panel ordered separately.