

Rigid Conduit/IMC Fittings

Conduit Bushings — Die-Cast Zinc — Insulated

- 105° C thermoplastic liners
- Heavy reinforced ribs




CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BU-801	1/2	1.06	.43	1,000
BU-802	3/4	1.31	.43	1,000
BU-803	1	1.59	.48	500
BU-804	1 1/4	1.96	.56	250
BU-805	1 1/2	2.18	.60	250

UL File No. E-23018.



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BU-806	2	2.69	.56	250
BU-807	2 1/2	3.25	.90	50
BU-808	3	3.87	.85	25
BU-809	3 1/2	4.37	.93	25
BU-810	4	5.00	.93	10

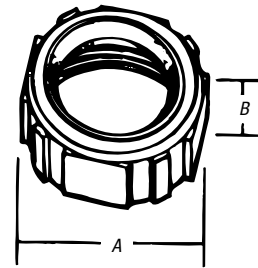

Conduit Bushings — Die-Cast Zinc — Heavy Reinforced Ribs




CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A (MIN.)	B (MAX.)	
BU201	1/2	1.05	.37	1,000
BU-202	3/4	1.32	.37	1,000
BU-203	1	1.58	.47	500
BU-204	1 1/4	1.94	.50	250
BU-205	1 1/2	2.20	.52	250

UL File No. E-23018.



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A (MIN.)	B (MAX.)	
BU-206	2	2.69	.52	250
BU-207	2 1/2	3.23	.85	50
BU-208	3	3.84	.85	25
BU-209	3 1/2	4.35	.85	25
BU-210	4	5.02	.85	10

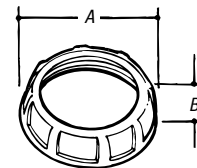

Insulated Bushings — Thermoplastic




CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BU-501	1/2	1 3/32	1 1/16	400
BU-502	3/4	1 3/32	1 1/64	400
BU-503	1	1 5/16	1 1/16	200
BU-504	1 1/4	1 9/16	1 29/32	100
BU-505	1 1/2	1 11/16	2 1/16	100
BU-506	2	2 1/8	2 11/16	60

UL File No. E-23018 1/2"-4" only.
Rated 105° C.



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BU-507	2 1/2	2 3/32	3 3/16	20
BU-508	3	3 1/16	3 27/32	20
BU-509	3 1/2	3 3/4	4 23/64	5
BU-510	4	4 29/32	4 27/32	5
BU-511	5	5 1	6 1/16	5
BU-512	6	6 1	7 1/16	5

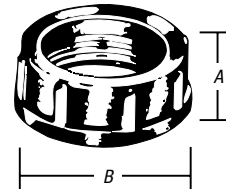

Bushings — Iron/Zinc Plated




CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BU-401	1/2	1 1/32	7/16	1,000
BU-402	3/4	1 1/4	7/16	1,000
BU-403	1	1 9/16	1/2	500
BU-404	1 1/4	1 13/16	1 1/32	200
BU-405	1 1/2	2 1/64	9/16	100
BU-406	2	2 5/64	9/16	50

UL File No. E-23018.



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BU-401	1/2	1 1/32	7/16	1,000
BU-402	3/4	1 1/4	7/16	1,000
BU-403	1	1 9/16	1/2	500
BU-404	1 1/4	1 13/16	1 1/32	200
BU-405	1 1/2	2 1/64	9/16	100
BU-406	2	2 5/64	9/16	50

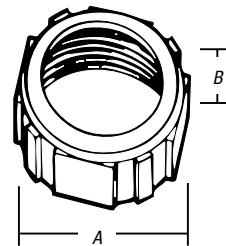

Grounding Bushings — Die-Cast Zinc — Insulated with Aluminum Lay-in Type Lug

- 105° C thermoplastic liners
- Heavy reinforced ribs



CAT. NO.	TRADE SIZE (IN.)	GROUNDING LUG WIRE SIZE		STD. CTN.
		MIN.	MAX.	
BG201	1/2	14 AWG	4 AWG	500
BG-202	3/4	14 AWG	4 AWG	500
BG-203	1	14 AWG	4 AWG	250
BG-204A	1 1/4	14 AWG	4 AWG	200
BG-204	1 1/4	8 AWG	1/0 AWG	200
BG-205A	1 1/2	11 AWG	4 AWG	100
BG-205	1 1/2	8 AWG	1/0 AWG	50
BG-206A	1	14 AWG	4 AWG	100
BG-206	2	8 AWG	1/0 AWG	50

UL File No. E-3060.



CAT. NO.	TRADE SIZE (IN.)	GROUNDING LUG WIRE SIZE		STD. CTN.
		MIN.	MAX.	
BG-207	2 1/2	8 AWG	1/0 AWG	50
BG-207A	2 1/2	6 AWG	250 kcmil	50
BG-208	3	8 AWG	1/0 AWG	50
BG-208A	3	6 AWG	250 kcmil	50
BG-209	3 1/2	8 AWG	1/0 AWG	10
BG-209A	3 1/2	6 AWG	250 kcmil	10
BG-210	4	8 AWG	1/0 AWG	10
BG-210A	4	6 AWG	250 kcmil	10

