

Switch Boxes and Accessories


Easy Depth Adjustment After Wall Covering Installation.

Adjust-A-Box®


The Adjust-A-Box System adapts to a variety of wall coverings. Its unique design enables the installer to adjust the box to various depths with the turn of a screw.

Features:

- Unique design allows for adjustment of depth after the wall covering has been installed
- Adjusts to any wall covering
- Mounts square and secure every time
- Removes easily to enable inner-wall access
- Accommodates high- and low-voltage applications
- Pre-installed ground screw
- Accommodates non-metallic cable, flexible metal cable and EMT

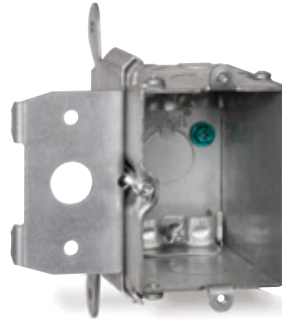

MB120ADJ

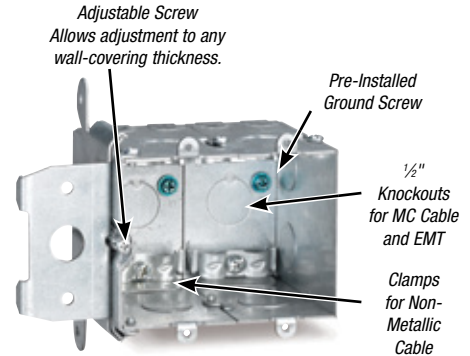

MB238ADJ

Installation:

Screw bracket to stud



Single-Gang



Two-Gang

Adjust box in or out to any wall thickness



Single-Gang



Two-Gang



CAT. NO.	VOLUME (CU. IN.)	DESCRIPTION	KNOCKOUTS	SIZE (IN.)	STD. CTN.	STD. WT. (LBS.)
MB120ADJ	20	One-Gang Adjustable Wall Box	1/2" (5)	2.20W x 3.28H x 3.52D	18	19.25
MB238ADJ	38	Two-Gang Adjustable Wall Box	1/2" (8)	4.01W x 3.28H x 3.52D	12	17.60

3 3/4" x 2" Switch Boxes

CAT. NO.	DEPTH (IN.)	CU. IN. CAPACITY	CLAMPS	EARS	BRKTS.	KNOCKOUTS	STD. CTN.
Non-Gangable							
SSV	1	6.5	—	—	Flat	2 pry-outs one end	25
SSQV	1	6.5	Yes	—	Flat	2 pry-outs one end with non-metallic cable clamps	25

Not UL Listed.



SSV

SSQV with non-metallic sheathed cable clamps




Switch Boxes and Accessories

3" x 2" Switch Boxes



SWB-25
Ears flush
for old work

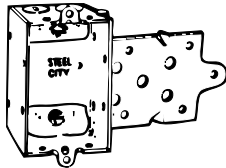

811-SW-25
S bracket recessed 5/8"



LXMWOW-25
Ears flush
for old work




LCOW-25
Ears flush
old work



LCOWC
Adapts to any wall
thickness up to 3/4"




LCLE-25

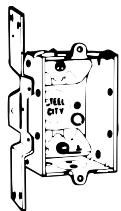


LCV-25
CV bracket
recessed 3/4"



LCNOW-25
Ears flush
for old work

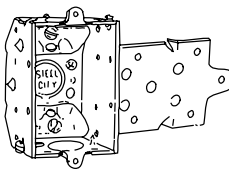


802-S
S bracket recessed 5/8"

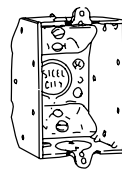

A12-25



A12E-25
Ears flush

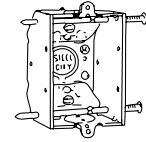

A16-25
With nails



LXWOW-25
Ears flush
for old work



LXWOWP



LXWLE-25



LXWOWC-25
Adapts to any wall
thickness up to 3/4"



LXWSV
SV bracket
recessed 7/16"



LXWV-25
CV bracket
recessed 7/8"


With Non-Metallic Sheathed Cable Clamps

CAT. NO.	DEPTH (IN.)	GANGABLE	CU. IN. CAPACITY	CLAMPS	EARS	BRKTS.	KNOCKOUTS (IN.)					STD. CTN.
							EA. END CONDUIT	EA. END CABLE	CABLE	BOTTOM CABLE	BOTTOM CONDUIT	
SWB-25	1½	—	7.5	C-5	Yes	—	—	2	—	2	—	25
811 SW-25	1½	—	7.5	C-5	—	S	—	2	—	2	—	50
LXMWOW-25	2	Yes	10.5	C-5	Yes	—	—	2	—	—	1-½	25
LCOW-25*	2¼	Yes	10.5	C-1	Yes	—	1-½	—	2	—	1-½	25
LCOWC*	2¼	Yes	10.5	C-1	Yes	—	1-½	—	2	—	1-½	25
LCLE-25*	2¼	Yes	10.5	C-1	—	—	1-½	—	2	—	1-½	25
LCV-25*	2¼	Yes	10.5	C-1	—	CV	1-½	—	2	—	1-½	25
LCNOW-25*	2¼	Yes	10.5	C-1	Yes	—	1-½	—	2	—	1-½	25
802 S*	2¼	Yes	10.5	C-1	—	S	1-½	—	2	—	1-½	25
A12-25	2¼	—	10.5	C-1	—	—	1-½	—	2	—	1-½	25
A12E-25	2¼	—	10.5	C-1	Yes	—	1-½	—	2	—	1-½	25
A16-25	2¼	—	10.5	C-1	—	—	1-½	—	2	—	1-½	25
LXWOW-25	2½	Yes	12.5	C-5	Yes	—	1-½	—	2	—	1-½	25
LXWOWP	2½	Yes	12.5	C-5	Yes	—	1-½	—	2	—	1-½	25
LXWLE-25	2½	Yes	12.5	C-5	—	—	1-1½	1-½	2	—	1-½	25
LXWOWC-25	2½	Yes	12.5	C-5	Yes	—	1-½	—	2	—	1-½	25
LXWSV	2½	Yes	12.5	C-5	—	SV	1-½	1-½	2	—	1-½	25
LXWV-25	2½	Yes	12.5	C-5	—	CV	1-½	1-1½	2	—	1-½	25

* Beveled corners.

Switch Boxes and Accessories


3" x 2" Switch Boxes (continued)

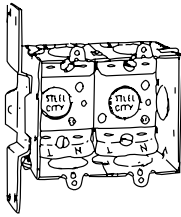


LXWV 2G
2-gang with CV
bracket recessed 1/8"




806 SW
S bracket recessed 1/8"

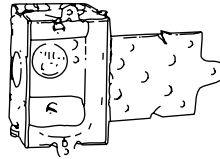

806 SW 1/4
S bracket recessed 1/8"

 

A254-25

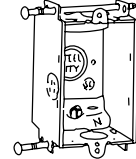

A257-25
With nails slanted
for easy drive-in




A-258
Without nails



CWN-25
Ears flush



CWNLE

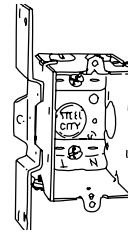


CWNV-25
CV bracket
recessed 1/8"




CXWLE



CXWOW
Ears flush
for old work

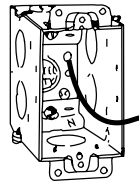

CXWOWP

 

CXWV
CV bracket
recessed 1/8"



CXWVP

With Non-Metallic Sheathed Cable Clamps (continued)

CAT. NO.	DEPTH (IN.)	GANGABLE	CU. IN. CAPACITY	CLAMPS	EARS	BRKTS.	KNOCKOUTS (IN.)					STD. CTN.
							EA. END CONDUIT	EA. END CABLE	CABLE	BOTTOM CABLE	BOTTOM CONDUIT	
LXWV 2G	2 1/2	Yes	12.5	C-5	—	CV	1-1/2	2-1/2	4	—	2-1/2	25
806 SW	2 1/2	Yes	12.5	C-5	—	S	1-1/2	1-1/2	2	—	1-1/2	25
806 SW 1/4	2 1/2	Yes	12.5	C-5	—	S	1-1/2	1-1/2	2	—	1-1/2	25
A254-25	2 1/2	—	12.5	C-5	—	—	—	1-1/2	2	—	1-1/2	25
A257-25	2 1/2	—	12.5	C-5	—	—	—	1-1/2	2	—	1-1/2	25
A-258	2 1/2	—	12.5	C-5	—	—	—	1-1/2	2	—	1-1/2	25
CWN-25	2 1/2	Yes	14.0	C-5	Yes	—	1-1/2	—	2	—	1-1/2	25
CWNLE	2 1/2	Yes	14.0	C-5	—	—	1-1/2	—	2	—	1-1/2	25
CWNV-25	2 1/2	Yes	14.0	C-5	—	CV	1-1/2	—	2	—	1-1/2	25
CXWLE	3 1/2	Yes	18.0	C-5	—	—	2-1/2	1-1/2	2	—	1-1/2	25
CXWOW	3 1/2	Yes	18.0	C-5	Yes	—	2-1/2	1-1/2	2	—	1-1/2	25
CXWOWP	3 1/2	Yes	18.0	C-5	Yes	—	2-1/2	1-1/2	2	—	1-1/2	25
CXWV	3 1/2	Yes	18.0	C-5	—	CV	2-1/2	1-1/2	2	—	1-1/2	25
CXWVP	3 1/2	Yes	18.0	C-5	—	CV	2-1/2	1-1/2	2	—	1-1/2	25

Switch Boxes and Accessories

3" x 2" Switch Boxes (continued)



 
CDOW
Ears flush




CDOWTG-25
Ears flush



CDLE-25



CDV-25
CV bracket
recessed 1/8"

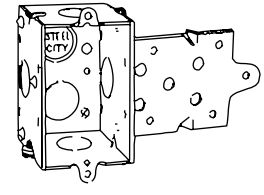

804 S
S bracket recessed 3/8"



 
CW 1/2
Ears flush




CW3/4-25
Ears flush



CWLE1/2-25




CWLE 3/4

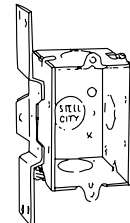


CWV 1/2
CV bracket
recessed 1/8"




CY 1/2
Ears flush

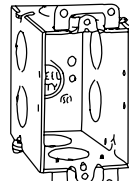

CY 3/4
Ears flush

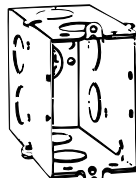

CYLE 1/2

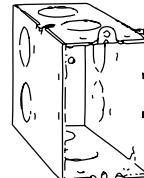

CYLE 3/4

With Conduit KOs

CAT. NO.	DEPTH (IN.)	GANGABLE	CU. IN. CAPACITY	EARS	BRKTS.	KNOCKOUTS (IN.)			STD. CTN.
						EA. END CONDUIT	EA. END CABLE	BOTTOM CONDUIT	
CDOW	2 1/2	Yes	12.5	Yes	—	1 1/2	1 1/2	2 1/2	50
CDOWTG-25	2 1/2	Yes	12.5	Yes	—	1 1/2	1 1/2	2 1/2	25
CDLE-25	2 1/2	Yes	12.5	—	—	1 1/2	1 1/2	2 1/2	25
CDV-25	2 1/2	Yes	12.5	—	CV	1 1/2	1 1/2	2 1/2	25
804 S	2 1/2	Yes	12.5	—	S	1 1/2	1 1/2	2 1/2	25
CW 1/2	2 3/4	Yes	14.0	Yes	—	1-3/4	1-3/4	1-3/4	50
CW3/4-25	2 3/4	Yes	14.0	Yes	—	1-3/4	1-3/4	1-3/4	25
CWLE1/2-25	2 3/4	Yes	14.0	—	—	1-3/4	1-3/4	1-3/4	25
CWLE 3/4	2 3/4	Yes	14.0	—	—	1-3/4	1-3/4	1-3/4	25
CWV 1/2	2 3/4	Yes	14.0	—	CV	1-3/4	1-3/4	1-3/4	25
CY 1/2	3 1/2	Yes	18.0	Yes	—	2-3/4	2-3/4	1-3/4	25
CY 3/4	3 1/2	Yes	18.0	Yes	—	2-3/4	2-3/4	1-3/4	25
CYLE 1/2	3 1/2	Yes	18.0	—	—	2-3/4	2-3/4	1-3/4	25
CYLE 3/4	3 1/2	Yes	18.0	—	—	2-3/4	2-3/4	1-3/4	25

Switch Boxes and Accessories

3" x 2" Switch Boxes (continued)

Boxes & Covers — Steel City® Metallic Boxes



LXMOV-25
Ears flush
for old work



LXOW-25
Ears flush
for old work




LXOWC-25
Adapts to 3/4"
wall thickness




LXLE




LXV-25
CV bracket
recessed 1/8"

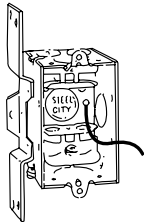

LXVP

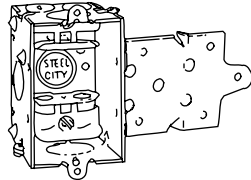

806 S
S bracket recessed 3/8"

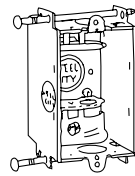

A-256
With nails slanted
for easy drive-in




CWX-25
Ears flush




CWXV-25
CV bracket
recessed 1/8"



CX
Ears flush

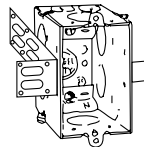

CXLE-SSX
For metal stud

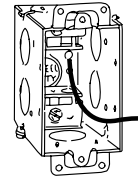

CXP



CXV
CV bracket
recessed 3/8"

With Armored Cable/Metal Clad Clamps

CAT. NO.	DEPTH (IN.)	GANGABLE	CU. IN. CAPACITY	CLAMPS	EARS	BRKTS.	KNOCKOUTS (IN.)				STD. CTN.
							EA. END CONDUIT	EA. END CABLE	CABLE	BOTTOM CONDUIT	
LXMOV-25	2	Yes	10.5	C-3	Yes	—	—	2	—	1-1/2	25
LXOW-25	2 1/2	Yes	12.5	C-3	Yes	—	1-1/2	—	2	1-1/2	25
LXOWC-25	2 1/2	Yes	12.5	C-3	Yes	—	1-1/2	—	2	1-1/2	25
LXLE	2 1/2	Yes	12.5	C-3	—	—	1-1/2	1-1/2	2	1-1/2	25
LXV-25	2 1/2	Yes	12.5	C-3	—	CV	1-1/2	1-1/2	2	1-1/2	25
LXVP	2 1/2	Yes	12.5	C-3	—	CV	1-1/2	1-1/2	2	1-1/2	25
806 S	2 1/2	Yes	12.5	C-3	—	S	1-1/2	1-1/2	2	1-1/2	25
A-256	2 1/2	—	12.5	C-3	—	—	—	1-1/2	2	1-1/2	25
CWX-25	2 3/4	Yes	14.0	C-3	Yes	—	1-1/2	—	2	1-1/2	25
CWXV-25	2 3/4	Yes	14.0	C-3	—	CV	1-1/2	—	2	1-1/2	25
CX	3 1/2	Yes	18.0	C-3	Yes	—	2-1/2	1-1/2	2	1-1/2	25
CXLE-SSX	3 1/2	Yes	18.0	C-3	No	SSX	2-1/2	1-1/2	2	1-1/2	25
CXP	3 1/2	Yes	18.0	C-3	Yes	—	2-1/2	1-1/2	2	1-1/2	25
CXV	3 1/2	Yes	18.0	C-3	—	CV	2-1/2	1-1/2	2	1-1/2	25