


Electrical metallic tubing (EMT) fittings

Set-screw couplings

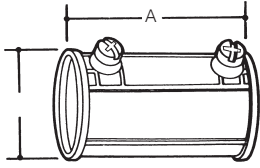

Features and benefits:

- Concrete tight when taped




Set-screw couplings – die-cast zinc

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
TK-221	1/2	1 ³³ / ₆₄	5 ⁹ / ₆₄	500
TK-222	3/4	1 ²⁹ / ₃₂	1 ⁵ / ₃₂	250
TK-223	1	2	1 ⁷ / ₁₆	200
TK-224	1 1/4	2 ³³ / ₆₄	1 ²⁷ / ₃₂	100
TK-225	1 1/2	2 ²⁷ / ₃₂	2 ¹ / ₁₆	40
TK-226A	2	3 ¹³ / ₃₂	2 ¹ / ₂	20
TK-227	2 1/2	4 ⁷ / ₃₂	3 ¹⁹ / ₆₄	12
TK-228	3	4 ¹¹ / ₁₆	4 ³ / ₆₄	12
TK-229	3 1/2	4 ²⁷ / ₃₂	4 ¹⁷ / ₃₂	10
TK-2210	4	5 ¹⁵ / ₃₂	4 ⁹ / ₁₆	6


UL File No. E-16592 – 1/2"-2". UL File No. E-23018 – 2 1/2"-4".
 CSA File No. LR-12798 – 1/2"-1 1/4", 2 1/2"-4".

Compression connectors

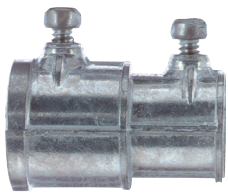

Features and benefits:

- Concrete tight when taped

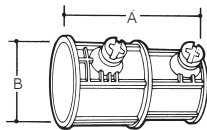


Combination set-screw couplings – Thinwall to Heavywall – die-cast zinc

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
HT-221	1/2 EMT to 1/2 Rigid	1.67	1.07	500
HT-222	3/4 EMT to 3/4 Rigid	1.98	1.29	250
HT-223	1 EMT to 1 Rigid	2.15	1.58	100

UL File No. E-23018.

Compression couplings

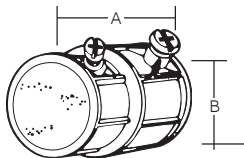

Combination set-screw couplings

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
Die-cast zinc flexible metal conduit to EMT				
TX-220	3/8 Flex to 3/8 EMT	1 ⁵ / ₈	1/2	500
TX-221	1/2 Flex to 1/2 EMT	1 ¹³ / ₁₆	1 ⁵ / ₃₂	250
TX-222	3/4 Flex to 3/4 EMT	1 ¹ / ₃₂	1 ¹¹ / ₃₂	150
TX-223	1 Flex to 1 NMT	2 ⁷ / ₆₄	1 ⁵ / ₈	150

UL File No. E-23018.

Combination couplings

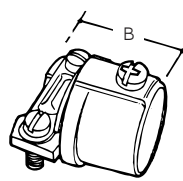


Fig. 1
1/2"-3/8"

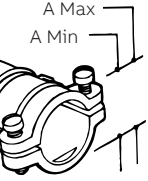
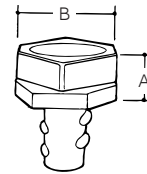



Fig. 2
1/2"-3/8" 3/4"-3/4"

Combination couplings

Cat. No.	Trade Fig.	Size (in.)	Dimensions (in.)			Std. Ctn.
			A (min.)	A (max.)	B	
EMT to flex set-screw type – die-cast zinc						
TX-210	1	1/2 - 3/8	0.15	0.61	1.16	250
TX-211	2	1/2 - 1/2	0.60	1.00	1.71	250
TX-212	2	3/4 - 3/4	0.78	1.20	1.93	200

Cat. No.	Trade Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
EMT to flex compression to screw-in type – die-cast zinc				
TX-201	1/2	0.84	1.10	500
TX-202	3/4	0.95	1.30	250


EMT to box set-screw types

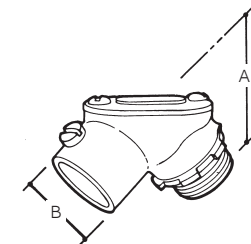

EMT to box set-screw type – die-cast zinc

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
EMT to flex compression to screw-in type – die-cast zinc				
TL-211	1/2	1.31	0.93	100
TL-212	3/4	1.47	1.22	50

UL File No. E-23018.

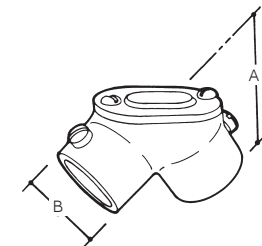

EMT to box set-screw type – die-cast zinc

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
EMT to flex compression to screw-in type – die-cast zinc				
TL-201	1/2	1.31	1.10	100
TL-202-SC	3/4	1.60	1.24	50
TL-203	1	1.94	1.59	25
TL-204	1 1/4	2.26	1.97	25

UL File No. E-23018.