
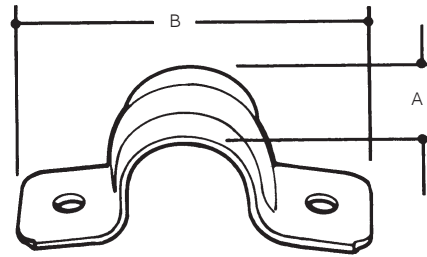


Electrical metallic tubing (EMT) fittings

EMT connectors, one-hole snap straps, two-hole EMT straps, space caps & nail straps

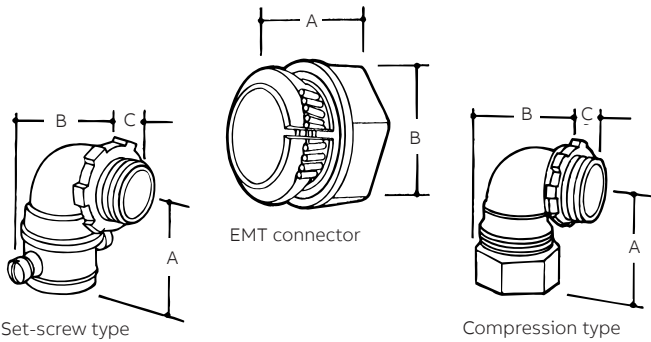

Two-hole EMT straps – steel – zinc plated – malleable insulated

EMT connectors – die-cast zinc


Cat. No.	Trade Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
Two-Piece Type				
TC-201-SC	1/2	0.68	1.05	1,000

UL File No. E16592.

Cat. No.	Trade Type (in.)	Size (in.)	Dimensions (in.)			Std. Ctn.
			A	B	C	
90° Angle						
TC921	Set-screw type	1/2	1.27	1.15	.45	200
TC-911-SC	Compression type	1/2	1.37	1.15	.45	200
TC-912-SC	Compression type	3/4	1.86	.95	.52	200

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Stainless Steel Std. Ctn.	Regular Std.Ctn.
		A	B		
TS-901	1/2	0.56	2.20	25	250
TS-902	3/4	0.62	2.67	25	200
TS-903	1	0.68	2.97	25	100
TS-904	1 1/4	0.75	3.67	10	50
TS-905	1 1/2	0.88	4.22	5	5
TS-906	2	1.00	4.91	5	25


Add SS suffix to part number for stainless steel.

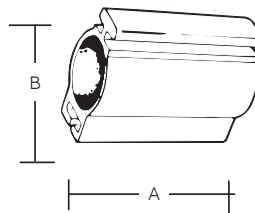


Space caps – plastic

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
BT-501	1/2	2 ¹⁵ / ₃₂	1 ³³ / ₆₄	100
BT-502	3/4	2 ¹⁵ / ₃₂	1 ⁴⁷ / ₆₄	100
BT-503	1	2 ¹⁵ / ₃₂	1 ³¹ / ₃₂	100
BT-504	1 1/4	2 ¹⁵ / ₃₂	2 ³¹ / ₆₄	100
BT-505	1 1/2	2 ¹⁵ / ₃₂	3 ¹ / ₃₂	100

UL File No. E16592.

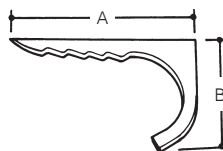

Nail straps – steel – zinc plated

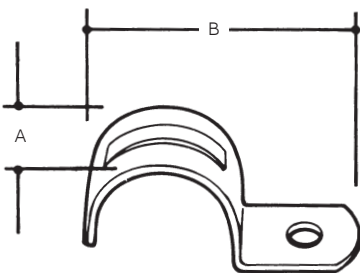

One-hole snap straps – steel – zinc plated

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Stainless Steel Std. Ctn.	Regular Std.Ctn.
		A	B		
EMT to flex compression to screw-in type – die-cast zinc					
TS 101	1/2	0.57	1.79	25	100
TS-102	3/4	0.62	1.96	25	50
TS-103	1	0.75	2.25	25	50
TS-104	1 1/4	0.88	2.85	10	25
TS-105	1 1/2	0.99	3.16	5	20
TS-106	2	1.10	3.93	5	10
HS-107	2 1/2	1.28	5.00	5	25
HS-108	3	1.28	5.55	5	25
HS-109	3 1/2	1.28	6.37	5	10
HS-110	4	1.28	6.87	5	10

Add SS suffix to part number for stainless steel.

Cat. No.	Rigid/ MC Size	EMT Size (in.)	Flex Size (in.)	Dimensions (in.)		Std. Ctn.
				A	B	
N-101-SC	–	1/2	3/8	1 ¹⁵ / ₁₆	1 ⁵ / ₆₄	1,000
N-102-SC	–	1/2	3/4	2 ³ / ₁₆	1 ¹⁷ / ₃₂	1,000
N-103-SC	–	3/4	1	2 ³ / ₈	1 ¹⁵ / ₃₂	1,000