


Rigid conduit/IMC fittings


Threadless compression connectors & couplings

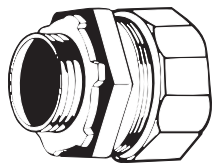

— Threadless compression connectors – malleable – iron-zinc plated 

Cat. No.	Conduit Size (in.)	Std. Ctn.
Die-cast zinc flexible metal conduit to EMT		
HC-401	1/2	300
HC-402	3/4	150
HC-403	1	90
HC-404	1 1/4	60
HC-405	1 1/2	30
HC-406	2	12
HC-407	2 1/2	12
HC-408	3	6
HC-409	3 1/2	6
HC-410	4	6

Suggested use – rigid conduit only.
UL File No. E-23018 – 1/2"-1 1/4".

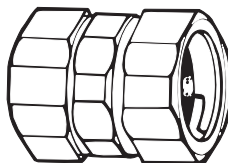


— Threadless compression couplings – malleable – iron-zinc plated 

Cat. No.	Conduit Size (in.)	Std. Ctn.
HK-401	1/2	300
HK-402	3/4	150
HK-403	1	90
HK-404	1 1/4	60
HK-405	1 1/2	30
HK-406	2	6
HK-407	2 1/2	6
HK-408	3	4
HK-409	3 1/2	4
HK-410	4	4

Suggested use – rigid conduit only.
UL File No. E-23018 – 1/2"-1 1/4".

Set-screw connectors

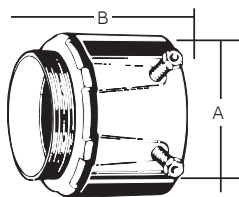

— Set-screw connectors – steel – zinc plated 

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
Die-cast zinc flexible metal conduit to EMT				
HC-101	1/2	1 1/8	1 1/8	100
HC-102	3/4	1 3/8	1 1/2	50
HC-103	1	5/8	1 13/16	50
HC-104	1 1/4	2	2	25
HC-105	1 1/2	2 1/2	2 3/8	25
HC-106	2	2 3/4	2 3/8	20
HC-107	2 1/2	3 13/32	3 5/16	10
HC-108	3	4 1/32	3 7/16	5
HC-109	3 1/2	4 9/16	3 13/16	5
HC-110	4	5 3/32	4 3/32	5

One set screw or two. Two set screws starting at 2" trade size.
Suggested use – rigid conduit only.
UL File No. E-23018 – 1/2"-1 1/4".

— Set-screw connectors – insulated – steel – zinc plated 

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
Die-cast zinc flexible metal conduit to EMT				
HC-701	1/2	1 1/8	1 1/8	100
HC-702	3/4	1 3/8	1 1/2	50
HC-703	1	5/8	1 13/16	25
HC-704	1 1/4	2	2	25
HC-705	1 1/2	2 1/2	2 3/8	25
HC-706	2	2 3/4	2 3/8	20
HC-707	2 1/2	3 13/32	3 5/16	10
HC-708	3	4 1/32	3 7/16	5
HC-709	3 1/2	4 1/4	4 7/8	5
HC-710	4	5 3/4	4 5/16	5

One set screw or two. Two set screws starting at 2" trade size.
Suggested use – rigid conduit only.
UL File No. E-23018 – 1/2"-1 1/4".