


Rigid conduit/IMC fittings

Bushings


Conduit bushings – die-cast zinc – insulated

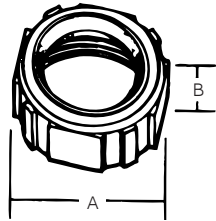

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
BU-801	1/2	1.06	0.43	1,000
BU-802	3/4	1.31	0.43	1,000
BU-803	1	1.59	0.48	500
BU-804	1 1/4	1.96	0.56	250
BU-805	1 1/2	2.18	0.60	250
BU-806	2	2.68	0.56	250
BU-807	2 1/2	3.25	0.90	50
BU-808	3	3.87	0.85	25
BU-809	3 1/2	4.37	0.93	25
BU-810	4	5.00	0.93	10

UL File No. 23018.


Bushings – iron/zinc plated

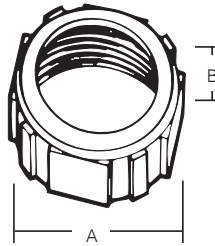

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
BU-401	1/2	1 1/32	7/16	1,000
BU-402	3/4	1 1/4	7/16	1,000
BU-403	1	1 9/16	1/2	500
BU-404	1 1/4	1 15/16	17/32	200
BU-405	1 1/2	2 13/64	9/16	100
BU-406	2	2 45/64	9/16	50

UL File No. 23018.


Conduit bushings – die-cast zinc – heavy reinforced ribs

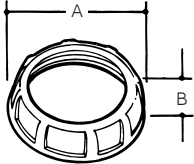

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A (Min.)	B (Max.)	
BU201	1/2	1.05	0.37	1,000
BU-202	3/4	1.32	0.37	1,000
BU-203	1	1.58	0.47	500
BU-204	1 1/4	1.94	0.50	250
BU-205	1 1/2	2.20	0.52	250
BU-206	2	2.69	0.52	250
BU-207	2 1/2	3.23	0.85	50
BU-208	3	3.84	0.85	25
BU-209	3 1/2	4.35	0.85	25
BU-210	4	5.02	0.85	10

UL File No. 23018.


Grounding bushings – die-cast zinc – insulated with aluminum lay-in type Lug

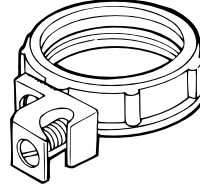

Cat. No.	Trade Size (in.)	Grounding Lug Wire Size		Std. Ctn.
		Min.	Max.	
BG201	1/2	14 AWG	4 AWG	500
BG-202	3/4	14 AWG	4 AWG	500
BG-203	1	14 AWG	4 AWG	250
BG-204A	1 1/4	14 AWG	4 AWG	200
BG-204	1 1/4	8 AWG	1/0 AWG	200
BG-205A	1 1/2	11 AWG	4 AWG	100
BG-205	1 1/2	8 AWG	1/0 AWG	50
BG-206A	1	14 AWG	4 AWG	100
BG-206	2	8 AWG	1/0 AWG	50
BG-207	2 1/2	8 AWG	1/0 AWG	50
BG-207A	2 1/2	6 AWG	250 kcmil	50
BG-208	3	8 AWG	1/0 AWG	50
BG-208A	3	6 AWG	250 kcmil	50
BG-209	3 1/2	8 AWG	1/0 AWG	10
BG-209A	3 1/2	6 AWG	250 kcmil	10
BG-210	4	8 AWG	1/0 AWG	10
BG-210A	4	6 AWG	250 kcmil	10

UL File No. 3060.

Insulated bushings – thermoplastic

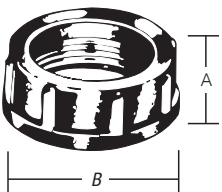

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
BU-501	1/2	13/32	1 1/16	400
BU-502	3/4	13/32	1 19/64	400
BU-503	1	9/16	1 9/16	200
BU-504	1 1/4	9/16	1 29/32	100
BU-505	1 1/2	9/16	2 3/16	100
BU-506	2	5/8	2 1/16	60
BU-507	2 1/2	23/32	3 3/16	20
BU-508	3	9/16	3 27/32	20
BU-509	3 1/2	3/4	4 23/64	5
BU-510	4	25/32	4 27/32	5
BU-511	5	1	6 5/16	5
BU-512	6	1	7 1/16	5

UL File No. E-23018 1/2" – 4" only.
Rated 105° C.