


Rigid conduit/IMC fittings

Pipe Straps

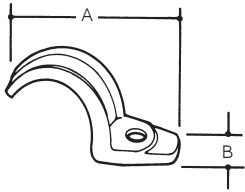


Pipe straps – malleable iron/zinc plated

Cat. No.	Screw Size	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
			A	B	
HS-400	10	3/8	1 ¹¹ / ₁₆	1 ⁷ / ₃₂	500
HS-401	1/4	1/2	2 ¹ / ₆₄	5/8	500
HS-402	1/4	3/4	2 ⁷ / ₁₆	1 ³ / ₁₆	500
HS-403	1/4	1	2 ⁷ / ₈	1 ⁵ / ₁₆	100
HS-404-SC	5/16	1 1/4	3 ⁵ / ₁₆	1 ¹ / ₃₂	100
HS-405	3/8	1 1/2	3 ³ / ₄	1 1/8	50
HS-406	1/2	2	4 ¹⁹ / ₃₂	1 ⁵ / ₁₆	25
HS-407	5/8	2 1/2	5 ¹¹ / ₁₆	1 ⁵ / ₈	25
HS-408	5/8	3	6 ⁷ / ₈	1 ⁷ / ₈	25
HS-409	5/8	3 1/2	7 ²³ / ₃₂	2 ¹ / ₈	10
HS-410	5/8	4	8 ⁹ / ₁₆	2 ³ / ₈	10
HS-411	5/8	5	10 ⁹ / ₃₂	2 ⁵ / ₈	5

Available in one-hole and two-hole in stainless steel. Add SS suffix to catalog number for stainless steel.

Nail Strap

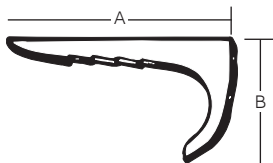

Nail strap – stamped steel/zinc plated


Cat. No.	Rigid/MC Size (in.)	EMT Size (in.)	Flex Size (in.)	Dimensions (in.)		Std. Ctn.
				A	B	
N-101-SC	–	1/2	3/8	2 ⁵ / ₃₂	1 ⁵ / ₆₄	1,000
N-102-SC	1/2	3/4	1/2	2 ⁵ / ₁₆	1 ⁷ / ₃₂	1,000
N-103-SC	3/4	1	–	2 ³ / ₈	1 ¹⁵ / ₃₂	1,000

Available in one-hole and two-hole in stainless steel. Add SS suffix to catalog number for stainless steel.

Flange plates

Flange plates – malleable iron/zinc plated


Cat. No.	Conduit		Depth B (in.)	Std. Ctn.
	Size (in.)	Dia. A (in.)		
FP-401	1/2	3	0.625	50
FP-402	3/4	3 ³ / ₈	0.656	50
FP-403	1	3 ⁵ / ₈	0.765	50
FP-404	1 1/4	4	0.875	25
FP-405	1 1/2	4 ³ / ₈	0.937	25
FP-406	2	4 ⁷ / ₈	0.843	25

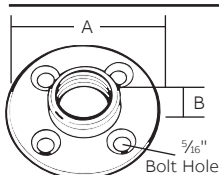

Pipe spacers

Pipe spacers for rigid/intermediate or thinwall – die-cast zinc


Cat. No.	Conduit		Depth B (in.)	Std. Ctn.
	Size (in.)	Dia. A (in.)		
CB-201	1/2	2	1	1,000
CB-202	3/4	2 ³ / ₈	1 ¹ / ₁₆	500
CB-203	1	2 ³ / ₄	1 ⁵ / ₁₆	500
CB-204	1 1/4	3 ³ / ₈	1 1/2	250
CB-205	1 1/2	3 ¹³ / ₁₆	1 ⁵ / ₈	100
CB-206	2	4 1/2	2	50

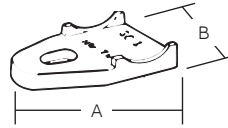

Rigid/intermediate space caps

Rigid/intermediate space caps – plastic

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
BR-501	1/2	2 ¹⁵ / ₃₂	1 ²¹ / ₃₂	100
BR-502	3/4	2 ¹⁵ / ₃₂	1 ⁵⁵ / ₆₄	100
BR-503	1	2 ¹⁵ / ₃₂	2 ¹ / ₈	100
BR-504	1 1/4	2 ¹⁵ / ₃₂	2 ⁶¹ / ₆₄	100
BR-505	1 1/2	2 ¹⁵ / ₃₂	3 ¹³ / ₆₄	100

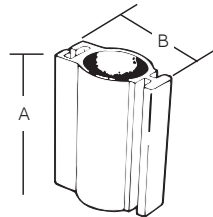

Snap-in blanks

Snap-in steel blanks - zinc plated

Cat. No.	Conduit Size (in.)	Diameter (in.)	Std. Ctn.
BL-112	3/4	1 1/4	1,000
BL-113	1	1 1/2	1,000
BL-114	1 1/4	1 ¹³ / ₁₆	500
BL-115	1 1/2	2 ⁷ / ₃₂	500
BL-116	2	2 ¹¹ / ₁₆	250



Box spacer

Box spacer – die-cast zinc (1/4" space)

Cat. No.	Conduit Size (in.)	Dimensions (in.)		Std. Ctn.
		A	B	
BS 201	1/2	1 ¹ / ₈	1 ¹³ / ₃₂	500

