


Accessories

6H Series conduit and pipe hangers

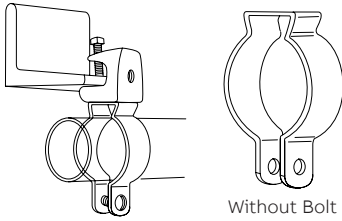

All Steel City 6H Hanger Bolts include a combination Slot-Phillips Head.

For hanging conduit (rigid or EMT) and pipe.
The 6H series hangers are fast, easy and economical to use. May be fastened directly to a #500 beam clamp through a hole in the base of the hanger by means of a 1/4-20 stove bolt or suspended on 1/4" hanger rod.

6H Series conduit and pipe hangers – without bolt




| Cat. No. | Rigid Conduit or Pipe Size (in.) | EMT Size (in.) | Dimensions (in.) | | | | Load Rating | Std. Ctn. |
|----------|----------------------------------|----------------|------------------|-------|---------------------------------|----------|-------------|-----------|
| | | | A | B | C | D (Dia.) | | |
| 6H0 | 3/8 - 1/2 | 1/2 | 3/4 | 0.045 | 1 ²¹ / ₃₂ | 9/32 | 500 | 100 |
| 6H0-T | 3/8 - 1/2 | 1/2 | 3/4 | 0.045 | 1 ²⁷ / ₃₂ | 9/32 | 500 | 100 |
| 6H1 | 3/4 | 3/4 | 7/8 | 0.045 | 1 ³¹ / ₃₂ | 9/32 | 500 | 100 |
| 6H1-T | 3/4 | 3/4 | 7/8 | 0.045 | 2 ⁹ / ₃₂ | 9/32 | 500 | 100 |
| 6H2 | 1 | 1 | 7/8 | 0.045 | 2 ³ / ₈ | 9/32 | 500 | 100 |
| 6H2 1/2 | - | 1 1/4 | 7/8 | 0.045 | 2 ²³ / ₃₂ | 9/32 | 500 | 100 |
| 6H3-SC | 1 1/4 | 1 1/2 | 7/8 | 0.045 | 2 ⁷ / ₈ | 9/32 | 500 | 100 |
| 6H4 | 1 1/2 | - | 1 | 0.071 | 3 ³ / ₈ | 11/32 | 500 | 100 |
| 6H5 | 2 | 2 | 1 1/4 | 0.071 | 3 ²⁹ / ₃₂ | 11/32 | 500 | 50 |
| 6H6 | 2 1/2 | - | 1 1/4 | 0.071 | 4 ⁹ / ₃₂ | 11/32 | 500 | 50 |
| 6H7 | 3 | - | 1 1/4 | 0.071 | 5 ³ / ₁₆ | 11/32 | 500 | 25 |
| 6H8 | 3 1/2 | - | 1 1/4 | 0.071 | 5 ⁷ / ₁₆ | 11/32 | 500 | 25 |
| 6H9 | 4 | 4 | 1 1/4 | 0.071 | 5 ⁷ / ₈ | 11/32 | 500 | 10 |

UL File No. E-160899.
Add SS suffix to catalog number for Type 302 Stainless Steel.
Load rating is 500 lbs. with a safety factor of 3. Available with or without closure bolt.
Standard finishes: Electro-Galvanized.

6H Series conduit and pipe hangers – with bolt



| Cat. No. | Rigid Conduit or Pipe Size (in.) | EMT Size (in.) | Dimensions (in.) | | | | Load Rating | Std. Ctn. |
|----------|----------------------------------|----------------|------------------|-------|---------------------------------|----------|-------------|-----------|
| | | | A | B | C | D (Dia.) | | |
| 6H0 B | 3/8 - 1/2 | 1/2 | 3/4 | 0.045 | 1 ²¹ / ₃₂ | 9/32 | 500 | 100 |
| 6H0 TB | 3/8 - 1/2 | 1/2 | 3/4 | 0.045 | 1 ²⁷ / ₃₂ | 9/32 | 500 | 100 |
| 6H1-B | 3/4 | 3/4 | 7/8 | 0.045 | 1 ³¹ / ₃₂ | 9/32 | 500 | 100 |
| 6H1-TB | 3/4 | 3/4 | 7/8 | 0.045 | 2 ⁹ / ₃₂ | 9/32 | 500 | 100 |
| 6H2-B | 1 | 1 | 7/8 | 0.045 | 2 ³ / ₈ | 9/32 | 500 | 100 |
| 6H2-TB | - | 1 1/4 | 7/8 | 0.045 | 2 ²³ / ₃₂ | 9/32 | 500 | 100 |
| 6H3-B | 1 1/4 | 1 1/2 | 7/8 | 0.045 | 2 ⁷ / ₈ | 9/32 | 500 | 100 |
| 6H4-B | 1 1/2 | - | 1 | 0.071 | 3 ³ / ₈ | 11/32 | 500 | 100 |
| 6H5-B | 2 | 2 | 1 1/4 | 0.071 | 3 ²⁹ / ₃₂ | 11/32 | 500 | 50 |
| 6H6-B | 2 1/2 | - | 1 1/4 | 0.071 | 4 ⁹ / ₃₂ | 11/32 | 500 | 50 |
| 6H7-B | 3 | - | 1 1/4 | 0.071 | 5 ³ / ₁₆ | 11/32 | 500 | 25 |
| 6H8-B | 3 1/2 | - | 1 1/4 | 0.071 | 5 ⁷ / ₁₆ | 11/32 | 500 | 25 |
| 6H9-B | 4 | 4 | 1 1/4 | 0.071 | 5 ⁷ / ₈ | 11/32 | 500 | 10 |

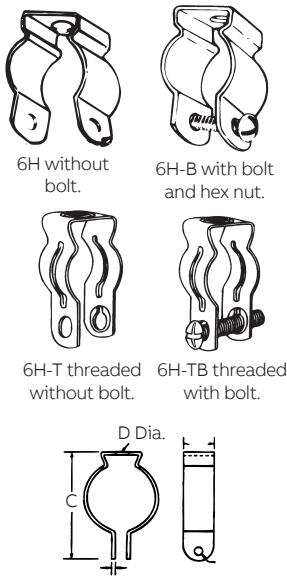

UL File No. E-160899.
Add SS suffix to catalog number for Type 302 Stainless Steel.
Load rating is 500 lbs. with a safety factor of 3. Available with or without closure bolt.
Available with or without closure bolt.
Standard finishes: Electro-Galvanized.