

- Variety of uses**
- Locking door**
- High impact resistance**
- Weather and UV resistant**

The access door on the multi-purpose protective cover is equipped with a lock enabling easy access while providing security from unauthorized persons. The cover utilizes a labyrinth seal for protection against dirt and moisture, and the unit is permanently attached to the enclosure from the inside.



**Application examples**



Protection for ventilation openings (i.e. pressure compensation)



As a cover for thermostats and regulators




As a tamper-proof cover for electronic input devices



Protection for electronic locks and security system keypads



Protection for power outlets

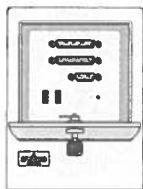

Cover and protection for data interfaces

**Technical Data**

**Housing**

High impact ASA plastic, light grey  
burning behavior according to UL 94H-B;  
high resistance to weather and UV light

**Operating / Storage temperature**


-49 to +158°F (-45 to +70°C)

**Dimensions**

8.8 x 6.5 x 2.6" (224 x 165 x 65mm)

**Protection type**

IP20

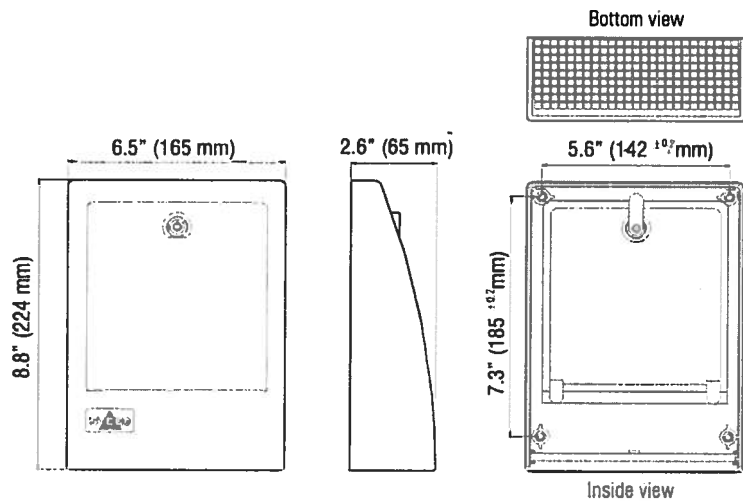

Part No.	Weight
08611.0-00	approx. 0.9 lbs. (0.4kg)

Specifications are subject to change without notice. Suitability of this product for its intended use and any associated risks must be determined by the end customer/ buyer in its final application.