




Stego, Inc.
 95 Chastain Road NW
 Suite 200
 Kennesaw, GA 30144, USA
Toll-Free: (888) 783-4611 • **Phone:** (770) 984-0858
Email: info@stegousa.com • **Website:** www.stego-usa.com

Part # 02700.9-02, PTC Fan Heater

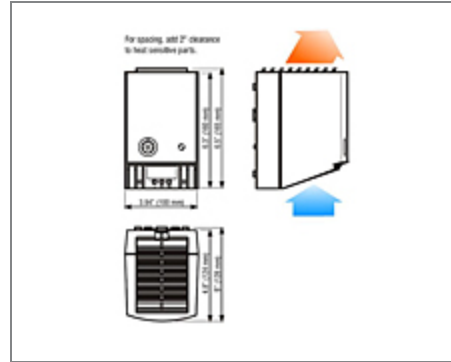

[Specifications](#) | [Technical Data](#)

Specifications

Power¹	550 W
Voltage	100 - 120 VAC
Max. Current	14 A (inrush)
Thermostat Range	32 to 140 °F
Fan	Continuously running
Agency Approvals	UL, VDE

Technical Data

Heating Element	PTC resistor, temperature limiting
Overheat Protection	built-in temperature limiter
Housing	Plastic, UL 94V-0, light gray
Axial Fan, Ball Bearing	50,000 h at 77 °F (25 °C)
Air Flow, Free Blowing	20 cfm (35 m ³ /h)

Function Control Light	LED
Connection	2-pole terminal, AWG 14 max (2.5 mm ²)
Mounting	Clip for 35 mm DIN rail (EN 60 715)
Position	Preferably vertical
Dimensions	6.5 x 3.94 x 5.0 inches (165 x 100 x 128 mm)
Weight	2.0 lb (900 g)
Operating/Storage Temperature	-49 to 158 °F (-45 to 70 °C)
Protection Type	IP20
Protection Class	II (double insulated)

¹ at 68 °F (20 °C) ambient temperature. Also, power will vary when frequency other than listed is applied (see Heating Power curves).