
 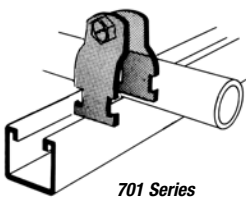

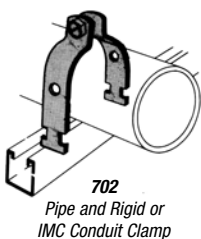
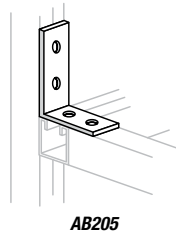
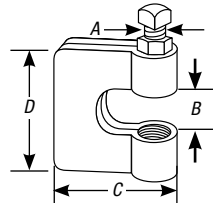
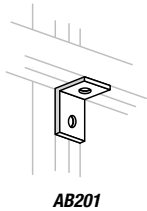
 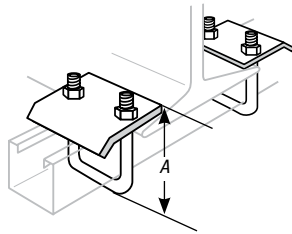


Special Metals and Finishes

Stainless Steel Products (continued)

Available in:

- Type 304 Stainless Steel — SS Suffix
- Type 316 Stainless Steel — SS6 Suffix



U501, U502

CAT. NO.	FOR CHANNEL	A (IN.)	STD. CTN.
U501	A-1200 A-1400	3 ³ / ₁₆	20
	B-1200 B-1400		
	C-1200 B-1402		
U502	A-1202 A-1402	4 ¹ / ₁₆	20
	C-1202 H-1200		

Furnished complete

Design Load U501 — 2150 lbs.

U502 — 3000 lbs.

C-775L — Clamp with Lock Nut

CAT. NO.	ROD SIZE (IN.)	DIMENSIONS (IN.)				DESIGN LOAD (LBS.)	STD. CTN.
		A	B	C	D		
C-775L	3/8	3/8	3/4	2 ³ / ₁₆	2 ³ / ₁₆	400	100
	1/2	2 ³ / ₁₆	2 ¹ / ₁₆	2 ¹ / ₁₆	2 ³ / ₁₆	500	100

H-104

- Hanger rod
- Continuous threaded

NATIONAL COARSE THREAD

CAT. NO.	SIZE (IN.)	THREADS PER INCH	DESIGN LOAD (LBS.)	STD. CTN.
H-104-1-1/4	1 ¹ / ₄	20	150	500
H-104-3/8	3/8	16	610	500
H-104-1/2	1/2	13	1,130	500
H-104-5/8	5/8	11	1,810	500
H-104-3/4	3/4	10	2,710	500
H-104-7/8	7/8	9	3,770	500
H-104-1	1	8	4,960	500

Standard lengths 12' only

Cobra® Clamp

CAT. NO.	FOR EMT AND RIGID CONDUIT	CABLE O.D. RANGE (IN.)	STATIC LOAD LIMIT (LB)	STD. CTN.
	TRADE SIZE (IN.)		SAFETY FACTOR = 4	
316 Stainless Steel				
CPC050SS6	1/2	.650-.890	200	100
CPC075SS6	3/4	.860-1.110	200	100
CPC100SS6	1	1.100-1.400	200	100
CPC125SS6	1 ¹ / ₄	1.400-1.725	200	50
CPC150SS6	1 ¹ / ₂	1.690-1.980	200	50
CPC200SS6	2	1.980-2.576	200	50
CPC250SS6	2 ¹ / ₂	2.576-3.060	350	25
CPC300SS6	3	3.060-3.626	350	25
CPC350SS6	3 ¹ / ₂	3.626-4.126	350	25
CPC400SS6	4	4.126-4.626	350	25