



Elite PAR Series

Black Housing

An additional option to our award-winning PAR portfolio. Black housing now available through our Assemble-To-Order program.

Limitless options for the following applications:

- Track Lights
- Recessed Downlights
- Display Lights
- Outdoor Fixtures that protect lamps from the elements

Great features and benefits:

- Energy Efficient: Up to 85% less energy than halogen replacements
- Smooth, uniform dimming
- Long Life: 25,000 hours
- 120W, 90W, 75W, 60W and 50W replacements
- Smooth black outer housing
- Excellent color consistency and high color rendering (CRI)
- Available in 2400K, 2700K, 3000K, 3500K and 4100K



PAR38

PAR30LN

PAR30SN

PAR20



LED 25,000 hours average rated life, 120 volts

Applications

Ideal for PAR38, PAR30, and PAR20 flood and spot light applications.


- + Track Lights
- + Recessed Downlights
- + Display Lights
- + Outdoor Fixtures that protect lamps from the elements



Features

Benefits

| | |
|---|--|
| Up to 85% less energy than halogen alternatives | Instant energy savings |
| Long life | Minimizes replacement and maintenance costs |
| Unique full face optic | Provides designer-grade light quality with same look as halogen replacement |
| Smooth, clean outside housing | Seamlessly blends into lighting applications |
| Very low heat generation | Perfect for sensitive display lighting such as art galleries |
| Excellent Color Consistency and CRI | Enhances colors of focal point while maintaining uniformity throughout lighting installation from lamp to lamp |
| Low weight | Track or down light installations are not strained by excess weight |
| UL approved for damp location | Can be used outdoors when protected from the elements— withstands humidity indoors/outdoors |
| Shatter resistant | Lower the risk of injury and breakage |

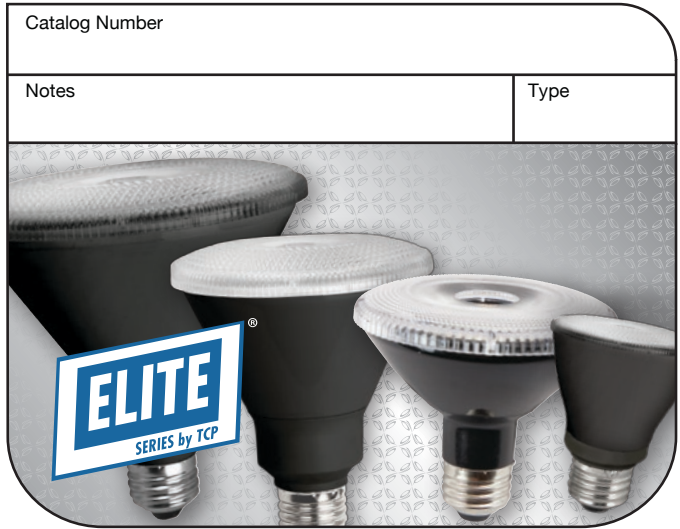

Specifications

| | PAR38 | PAR30LN | PAR30SN | PAR20 |
|------------------------|------------|------------|------------|------------|
| Input Line Voltage: | 120 VAC | 120 VAC | 120 VAC | 120 VAC |
| Input Power | 17 & 14 W | 14 & 12 W | 12 & 10 W | 10 & 8 W |
| Input Line Frequency | 50/60HZ | 50/60HZ | 50/60HZ | 50/60HZ |
| Lamp Life (Rated) | 25,000 hrs | 25,000 hrs | 25,000 hrs | 25,000 hrs |
| Minimum Starting Temp | -30°C | -30°C | -30°C | -30°C |
| Maximum Operating Temp | 40°C | 40°C | 40°C | 40°C |

Lens Angles



PAR38



PAR30LN



PAR30SN



PAR20



5 YEAR WARRANTY





| Item # | Description | Voltage | Wattage | Incandescent Wattage Comparison | Lumens | LPW | CBCP | Beam Angle | CCT | CRI | M.O.L. (inches) | Diameter (inches) | Case Quantity | STK/MTO |
|------------------|--|---------|---------|---------------------------------------|--------|------|-------|---------------|-------|-----|--------------------|----------------------|------------------|---------|
| PAR38 | | | | | | | | | | | | | | |
| LED17P38D24KFLB | Dimmable 17W Smooth PAR38 - 2400K 40°, Black | 120 | 17 | 120 | 1200 | 70.6 | 2132 | 40 | 2400K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D27KFLB | Dimmable 17W Smooth PAR38 - 2700K 40°, Black | 120 | 17 | 120 | 1200 | 70.6 | 2563 | 40 | 2700K | 80 | 5.3 | 4.8 | 12 | STK |
| LED17P38D27KNFLB | Dimmable 17W Smooth PAR38 - 2700K 25°, Black | 120 | 17 | 120 | 1200 | 70.6 | 5710 | 25 | 2700K | 80 | 5.3 | 4.8 | 12 | STK |
| LED17P38D27KSPB | Dimmable 17W Smooth PAR38 - 2700K 15°, Black | 120 | 17 | 90 | 1200 | 70.6 | 8338 | 15 | 2700K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D30KFLB | Dimmable 17W Smooth PAR38 - 3000K 40°, Black | 120 | 17 | 120 | 1250 | 73.5 | 3107 | 40 | 3000K | 80 | 5.3 | 4.8 | 12 | STK |
| LED17P38D30KNFLB | Dimmable 17W Smooth PAR38 - 3000K 25°, Black | 120 | 17 | 120 | 1250 | 73.5 | 6130 | 25 | 3000K | 80 | 5.3 | 4.8 | 12 | STK |
| LED17P38D30KSPB | Dimmable 17W Smooth PAR38 - 3000K 15°, Black | 120 | 17 | 90 | 1250 | 73.5 | 8658 | 15 | 3000K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D35KFLB | Dimmable 17W Smooth PAR38 - 3500K 40°, Black | 120 | 17 | 120 | 1275 | 75.0 | 3132 | 40 | 3500K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D35KNFLB | Dimmable 17W Smooth PAR38 - 3500K 25°, Black | 120 | 17 | 120 | 1275 | 75.0 | 7550 | 25 | 3500K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D35KSPB | Dimmable 17W Smooth PAR38 - 3500K 15°, Black | 120 | 17 | 90 | 1275 | 75.0 | 8771 | 15 | 3500K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D41KFLB | Dimmable 17W Smooth PAR38 - 4100K 40°, Black | 120 | 17 | 120 | 1300 | 76.5 | 3366 | 40 | 4100K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D41KNFLB | Dimmable 17W Smooth PAR38 - 4100K 25°, Black | 120 | 17 | 120 | 1300 | 76.5 | 7292 | 25 | 4100K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D41KSPB | Dimmable 17W Smooth PAR38 - 4100K 15°, Black | 120 | 17 | 90 | 1300 | 76.5 | 9947 | 15 | 4100K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D50KFLB | Dimmable 17W Smooth PAR38 - 5000K 40°, Black | 120 | 17 | 120 | 1300 | 76.5 | 3183 | 40 | 5000K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D50KNFLB | Dimmable 17W Smooth PAR38 - 5000K 25°, Black | 120 | 17 | 120 | 1300 | 76.5 | 7043 | 25 | 5000K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED17P38D50KSPB | Dimmable 17W Smooth PAR38 - 5000K 15°, Black | 120 | 17 | 90 | 1300 | 76.5 | 10989 | 15 | 5000K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D27KFLB | Dimmable 14W Smooth PAR38 - 2700K 40°, Black | 120 | 14 | 90 | 1050 | 75.0 | 2858 | 40 | 2700K | 80 | 5.3 | 4.8 | 12 | STK |
| LED14P38D27KNFLB | Dimmable 14W Smooth PAR38 - 2700K 25°, Black | 120 | 14 | 90 | 1050 | 75.0 | 5583 | 25 | 2700K | 80 | 5.3 | 4.8 | 12 | STK |
| LED14P38D27KSPB | Dimmable 14W Smooth PAR38 - 2700K 15°, Black | 120 | 14 | 90 | 1050 | 75.0 | 10949 | 15 | 2700K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D30KFLB | Dimmable 14W Smooth PAR38 - 3000K 40°, Black | 120 | 14 | 90 | 1100 | 78.6 | 2846 | 40 | 3000K | 80 | 5.3 | 4.8 | 12 | STK |
| LED14P38D30KNFLB | Dimmable 14W Smooth PAR38 - 3000K 25°, Black | 120 | 14 | 90 | 1100 | 78.6 | 6721 | 25 | 3000K | 80 | 5.3 | 4.8 | 12 | STK |
| LED14P38D30KSPB | Dimmable 14W Smooth PAR38 - 3000K 15°, Black | 120 | 14 | 90 | 1100 | 78.6 | 11300 | 15 | 3000K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D35KFLB | Dimmable 14W Smooth PAR38 - 3500K 40°, Black | 120 | 14 | 90 | 1125 | 80.4 | 3469 | 40 | 3500K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D35KNFLB | Dimmable 14W Smooth PAR38 - 3500K 25°, Black | 120 | 14 | 90 | 1125 | 80.4 | 6970 | 25 | 3500K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D35KSPB | Dimmable 14W Smooth PAR38 - 3500K 15°, Black | 120 | 14 | 90 | 1125 | 80.4 | 10098 | 15 | 3500K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D41KFLB | Dimmable 14W Smooth PAR38 - 4100K 40°, Black | 120 | 14 | 90 | 1150 | 82.1 | 2612 | 40 | 4100K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D41KNFLB | Dimmable 14W Smooth PAR38 - 4100K 25°, Black | 120 | 14 | 90 | 1150 | 82.1 | 4546 | 25 | 4100K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D41KSPB | Dimmable 14W Smooth PAR38 - 4100K 15°, Black | 120 | 14 | 90 | 1150 | 82.1 | 11718 | 15 | 4100K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D50KFLB | Dimmable 14W Smooth PAR38 - 5000K 40°, Black | 120 | 14 | 90 | 1150 | 82.1 | 4621 | 40 | 5000K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D50KNFLB | Dimmable 14W Smooth PAR38 - 5000K 25°, Black | 120 | 14 | 90 | 1150 | 82.1 | 7611 | 25 | 5000K | 80 | 5.3 | 4.8 | 12 | MTO |
| LED14P38D50KSPB | Dimmable 14W Smooth PAR38 - 5000K 15°, Black | 120 | 14 | 90 | 1150 | 82.1 | 12147 | 15 | 5000K | 80 | 5.3 | 4.8 | 12 | MTO |
| PAR30 | | | | | | | | | | | | | | |
| LED14P30D24KFLB | Dimmable 14W Smooth PAR30 - 2400K 40°, Black | 120 | 14 | 75 | 1050 | 75.0 | 2513 | 40 | 2400K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D24KNFLB | Dimmable 14W Smooth PAR30 - 2400K 25°, Black | 120 | 14 | 75 | 1050 | 75.0 | 4417 | 25 | 2400K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D27KFLB | Dimmable 14W Smooth PAR30 - 2700K 40°, Black | 120 | 14 | 75 | 1050 | 75.0 | 3021 | 40 | 2700K | 80 | 4.8 | 3.8 | 12 | STK |
| LED14P30D27KNFLB | Dimmable 14W Smooth PAR30 - 2700K 25°, Black | 120 | 14 | 75 | 1050 | 75.0 | 5310 | 25 | 2700K | 80 | 4.8 | 3.8 | 12 | STK |
| LED14P30D27KSPB | Dimmable 14W Smooth PAR30 - 2700K 15°, Black | 120 | 14 | 75 | 1050 | 75.0 | 9033 | 15 | 2700K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D30KFLB | Dimmable 14W Smooth PAR30 - 3000K 40°, Black | 120 | 14 | 75 | 1100 | 78.6 | 2881 | 40 | 3000K | 80 | 4.8 | 3.8 | 12 | STK |
| LED14P30D30KNFLB | Dimmable 14W Smooth PAR30 - 3000K 25°, Black | 120 | 14 | 75 | 1100 | 78.6 | 8169 | 25 | 3000K | 80 | 4.8 | 3.8 | 12 | STK |
| LED14P30D30KSPB | Dimmable 14W Smooth PAR30 - 3000K 15°, Black | 120 | 14 | 75 | 1100 | 78.6 | 9328 | 15 | 3000K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D35KFLB | Dimmable 14W Smooth PAR30 - 3500K 40°, Black | 120 | 14 | 75 | 1125 | 80.4 | 3196 | 40 | 3500K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D41KFLB | Dimmable 14W Smooth PAR30 - 4100K 40°, Black | 120 | 14 | 75 | 1150 | 82.1 | 3154 | 40 | 4100K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D41KNFLB | Dimmable 14W Smooth PAR30 - 4100K 25°, Black | 120 | 14 | 75 | 1150 | 82.1 | 6813 | 25 | 4100K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D41KSPB | Dimmable 14W Smooth PAR30 - 4100K 15°, Black | 120 | 14 | 75 | 1150 | 82.1 | 9681 | 15 | 4100K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D50KFLB | Dimmable 14W Smooth PAR30 - 5000K 40°, Black | 120 | 14 | 75 | 1150 | 82.1 | 3212 | 40 | 5000K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D50KNFLB | Dimmable 14W Smooth PAR30 - 5000K 25°, Black | 120 | 14 | 75 | 1150 | 82.1 | 5872 | 25 | 5000K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED14P30D50KSPB | Dimmable 14W Smooth PAR30 - 5000K 15°, Black | 120 | 14 | 75 | 1150 | 82.1 | 10043 | 15 | 5000K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D27KFLB | Dimmable 12W Smooth PAR30 - 2700K 40°, Black | 120 | 12 | 75 | 850 | 70.8 | 1924 | 40 | 2700K | 80 | 4.8 | 3.8 | 12 | STK |
| LED12P30D27KNFLB | Dimmable 12W Smooth PAR30 - 2700K 25°, Black | 120 | 12 | 75 | 850 | 70.8 | 5473 | 25 | 2700K | 80 | 4.8 | 3.8 | 12 | STK |
| LED12P30D27KSPB | Dimmable 12W Smooth PAR30 - 2700K 15°, Black | 120 | 12 | 75 | 850 | 70.8 | 8402 | 15 | 2700K | 80 | 4.8 | 3.8 | 12 | MTO |

PAR30 continued next page





ELITE Series

LED PAR Lamps - Black Housing

Smooth Uniform Dimming

| Item # | Description | Voltage | Wattage | Incandescent Wattage Comparison | Lumens | LPW | CBCP | Beam Angle | CCT | CRI | M.O.L. (inches) | Diameter (inches) | Case Quantity | STK/MTO |
|--------------------|---|---------|---------|---------------------------------|--------|------|------|------------|-------|-----|-----------------|-------------------|---------------|---------|
| PAR30 cont. | | | | | | | | | | | | | | |
| LED12P30D30KFLB | Dimmable 12W Smooth PAR30 - 3000K 40°, Black | 120 | 12 | 75 | 875 | 72.9 | 2596 | 40 | 3000K | 80 | 4.8 | 3.8 | 12 | STK |
| LED12P30D30KNFLB | Dimmable 12W Smooth PAR30 - 3000K 25°, Black | 120 | 12 | 75 | 875 | 72.9 | 5523 | 25 | 3000K | 80 | 4.8 | 3.8 | 12 | STK |
| LED12P30D30KSPB | Dimmable 12W Smooth PAR30 - 3000K 15°, Black | 120 | 12 | 75 | 875 | 72.9 | 8437 | 15 | 3000K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D35KFLB | Dimmable 12W Smooth PAR30 - 3500K 40°, Black | 120 | 12 | 75 | 900 | 75.0 | 2608 | 40 | 3500K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D41KFLB | Dimmable 12W Smooth PAR30 - 4100K 40°, Black | 120 | 12 | 75 | 925 | 77.1 | 2759 | 40 | 4100K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D41KNFLB | Dimmable 12W Smooth PAR30 - 4100K 25°, Black | 120 | 12 | 75 | 925 | 77.1 | 6017 | 25 | 4100K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D41KSPB | Dimmable 12W Smooth PAR30 - 4100K 15°, Black | 120 | 12 | 75 | 925 | 77.1 | 7275 | 15 | 4100K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D50KFLB | Dimmable 12W Smooth PAR30 - 5000K 40°, Black | 120 | 12 | 75 | 950 | 79.2 | 2235 | 40 | 5000K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D50KNFLB | Dimmable 12W Smooth PAR30 - 5000K 25°, Black | 120 | 12 | 75 | 950 | 79.2 | 4088 | 25 | 5000K | 80 | 4.8 | 3.8 | 12 | MTO |
| LED12P30D50KSPB | Dimmable 12W Smooth PAR30 - 5000K 15°, Black | 120 | 12 | 75 | 950 | 79.2 | 7375 | 15 | 5000K | 80 | 4.8 | 3.8 | 12 | MTO |
| PAR30SN | | | | | | | | | | | | | | |
| LED12P30SD27KFLB | Dimmable 12W Smooth PAR30 Short Neck - 2700K 40°, Black | 120 | 12 | 75 | 850 | 70.8 | 2261 | 40 | 2700K | 80 | 3.5 | 3.8 | 12 | STK |
| LED12P30SD27KNFLB | Dimmable 12W Smooth PAR30 Short Neck - 2700K 25°, Black | 120 | 12 | 75 | 850 | 70.8 | 4333 | 25 | 2700K | 80 | 3.5 | 3.8 | 12 | STK |
| LED12P30SD27KSPB | Dimmable 12W Smooth PAR30 Short Neck - 2700K 15°, Black | 120 | 12 | 75 | 850 | 70.8 | 7274 | 15 | 2700K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD30KFLB | Dimmable 12W Smooth PAR30 Short Neck - 3000K 40°, Black | 120 | 12 | 75 | 875 | 72.9 | 2349 | 40 | 3000K | 80 | 3.5 | 3.8 | 12 | STK |
| LED12P30SD30KNFLB | Dimmable 12W Smooth PAR30 Short Neck - 3000K 25°, Black | 120 | 12 | 75 | 875 | 72.9 | 5630 | 25 | 3000K | 80 | 3.5 | 3.8 | 12 | STK |
| LED12P30SD30KSPB | Dimmable 12W Smooth PAR30 Short Neck - 3000K 15°, Black | 120 | 12 | 75 | 875 | 72.9 | 7705 | 15 | 3000K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD35KFLB | Dimmable 12W Smooth PAR30 Short Neck - 3500K 40°, Black | 120 | 12 | 75 | 900 | 75.0 | 2032 | 40 | 3500K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD35KNFLB | Dimmable 12W Smooth PAR30 Short Neck - 3500K 25°, Black | 120 | 12 | 75 | 900 | 75.0 | 5832 | 25 | 3500K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD41KFLB | Dimmable 12W Smooth PAR30 Short Neck - 4100K 40°, Black | 120 | 12 | 75 | 925 | 77.1 | 2235 | 40 | 4100K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD41KNFLB | Dimmable 12W Smooth PAR30 Short Neck - 4100K 25°, Black | 120 | 12 | 75 | 925 | 77.1 | 7159 | 25 | 4100K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD41KSPB | Dimmable 12W Smooth PAR30 Short Neck - 4100K 15°, Black | 120 | 12 | 75 | 925 | 77.1 | 7768 | 15 | 4100K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD50KFLB | Dimmable 12W Smooth PAR30 Short Neck - 5000K 40°, Black | 120 | 12 | 75 | 950 | 79.2 | 2500 | 40 | 5000K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD50KNFLB | Dimmable 12W Smooth PAR30 Short Neck - 5000K 25°, Black | 120 | 12 | 75 | 950 | 79.2 | 4792 | 25 | 5000K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED12P30SD50KSPB | Dimmable 12W Smooth PAR30 Short Neck - 5000K 15°, Black | 120 | 12 | 75 | 950 | 79.2 | 8045 | 15 | 5000K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD27KFLB | Dimmable 10W Smooth PAR30 Short Neck - 2700K 40°, Black | 120 | 10 | 60 | 700 | 70.0 | 2060 | 40 | 2700K | 80 | 3.5 | 3.8 | 12 | STK |
| LED10P30SD27KNFLB | Dimmable 10W Smooth PAR30 Short Neck - 2700K 25°, Black | 120 | 10 | 60 | 700 | 70.0 | 4427 | 25 | 2700K | 80 | 3.5 | 3.8 | 12 | STK |
| LED10P30SD27KSPB | Dimmable 10W Smooth PAR30 Short Neck - 2700K 15°, Black | 120 | 10 | 60 | 700 | 70.0 | 7408 | 15 | 2700K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD30KFLB | Dimmable 10W Smooth PAR30 Short Neck - 3000K 40°, Black | 120 | 10 | 60 | 725 | 72.5 | 2173 | 40 | 3000K | 80 | 3.5 | 3.8 | 12 | STK |
| LED10P30SD30KNFLB | Dimmable 10W Smooth PAR30 Short Neck - 3000K 25°, Black | 120 | 10 | 60 | 725 | 72.5 | 4799 | 25 | 3000K | 80 | 3.5 | 3.8 | 12 | STK |
| LED10P30SD30KSPB | Dimmable 10W Smooth PAR30 Short Neck - 3000K 15°, Black | 120 | 10 | 60 | 725 | 72.5 | 8181 | 15 | 3000K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD35KFLB | Dimmable 10W Smooth PAR30 Short Neck - 3500K 40°, Black | 120 | 10 | 60 | 750 | 75.0 | 2289 | 40 | 3500K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD35KNFLB | Dimmable 10W Smooth PAR30 Short Neck - 3500K 25°, Black | 120 | 10 | 60 | 750 | 75.0 | 4927 | 25 | 3500K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD41KFLB | Dimmable 10W Smooth PAR30 Short Neck - 4100K 40°, Black | 120 | 10 | 60 | 775 | 77.5 | 1894 | 40 | 4100K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD41KNFLB | Dimmable 10W Smooth PAR30 Short Neck - 4100K 25°, Black | 120 | 10 | 60 | 775 | 77.5 | 5539 | 25 | 4100K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD41KSPB | Dimmable 10W Smooth PAR30 Short Neck - 4100K 15°, Black | 120 | 10 | 60 | 775 | 77.5 | 7127 | 15 | 4100K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD50KFLB | Dimmable 10W Smooth PAR30 Short Neck - 5000K 40°, Black | 120 | 10 | 60 | 800 | 80.0 | 2432 | 40 | 5000K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD50KNFLB | Dimmable 10W Smooth PAR30 Short Neck - 5000K 25°, Black | 120 | 10 | 60 | 800 | 80.0 | 5844 | 25 | 5000K | 80 | 3.5 | 3.8 | 12 | MTO |
| LED10P30SD50KSPB | Dimmable 10W Smooth PAR30 Short Neck - 5000K 15°, Black | 120 | 10 | 60 | 800 | 80.0 | 7717 | 15 | 5000K | 80 | 3.5 | 3.8 | 12 | MTO |
| PAR20 | | | | | | | | | | | | | | |
| LED8P20D27KFLB | Dimmable 8W Smooth PAR20 - 2700K 40°, Black | 120 | 8 | 50 | 575 | 71.9 | 1210 | 40 | 2700K | 80 | 3.5 | 2.5 | 12 | STK |
| LED8P20D27KNFLB | Dimmable 8W Smooth PAR20 - 2700K 25°, Black | 120 | 8 | 50 | 575 | 71.9 | 2336 | 25 | 2700K | 80 | 3.5 | 2.5 | 12 | STK |
| LED8P20D30KFLB | Dimmable 8W Smooth PAR20 - 3000K 40°, Black | 120 | 8 | 50 | 600 | 75.0 | 1416 | 40 | 3000K | 80 | 3.5 | 2.5 | 12 | STK |
| LED8P20D30KNFLB | Dimmable 8W Smooth PAR20 - 3000K 25°, Black | 120 | 8 | 50 | 600 | 75.0 | 2463 | 25 | 3000K | 80 | 3.5 | 2.5 | 12 | STK |
| LED8P20D41KFLB | Dimmable 8W Smooth PAR20 - 4100K 40°, Black | 120 | 8 | 50 | 650 | 81.2 | 1327 | 40 | 4100K | 80 | 3.5 | 2.5 | 12 | STK |
| LED8P20D41KNFLB | Dimmable 8W Smooth PAR20 - 4100K 25°, Black | 120 | 8 | 50 | 650 | 81.2 | 2291 | 25 | 4100K | 80 | 3.5 | 2.5 | 12 | STK |
| LED8P20D50KFLB | Dimmable 8W Smooth PAR20 - 5000K 40°, Black | 120 | 8 | 50 | 675 | 84.4 | 1501 | 40 | 5000K | 80 | 3.5 | 2.5 | 12 | STK |
| LED8P20D450KNFLB | Dimmable 8W Smooth PAR20 - 5000K 25°, Black | 120 | 8 | 50 | 675 | 84.4 | 2059 | 25 | 5000K | 80 | 3.5 | 2.5 | 12 | STK |

