



LED Dimmable G25 Globe Lamps

LED Dimmable Globe	25,000 hours average rated life, 120 volts
---------------------------	--


Applications:

- + Vanity Strips
- + Pendant Lighting
- + Decorative



Features and Benefits

- Smooth, uniform dimming from 100% to 5%
- Energy efficient: Up to 80% less energy than standard incandescent
- Exceeds all industry performance requirements for non-standard lamps
- Long life: 25,000 hours (lasts at least 15 times longer than alternative)
- Very durable: solid state lighting technology significantly reduces lighting service & maintenance due to robust lighting design
- Excellent color consistency and high color rendering (CRI)

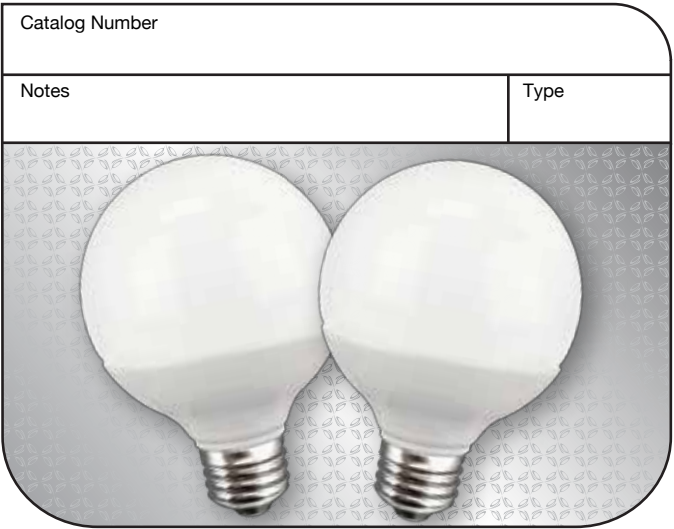

Specifications

Input Line Voltage:	120 VAC
Input Power	5W/6W
Input Line Frequency	50/60 HZ
Lamp Life (Rated)	25,000 hrs
Minimum Starting Temp	-20°C
Maximum Operating Temp	40°C

Warranties and Certifications:	Item #	Energy Star	Description	Voltage	Wattage	Wattage Equivalent	M.O.L. (inches)	Diameter (inches)	Lumens	LPW	Enclosed Luminaire	CCT	CRI
5 YEAR WARRANTY 	LED5G25D27KF	Yes	Dimmable 5W Smooth G25 2700K, Frosted	120	5	40	4.3	3.1	300	60.0	Yes	2700K	80
	LED5G25D30KF	Yes	Dimmable 5W Smooth G25 3000K, Frosted	120	5	40	4.3	3.1	325	65.0	Yes	3000K	80
	L6G25D2527KF	Yes	Dimmable 6W Smooth G25 2700K, Frosted	120	6	60	4.3	3.1	525	87.5	Yes	2700K	80
	L6G25D2530KF	No	Dimmable 8W Smooth G25 3000K, Frosted	120	6	60	4.3	3.1	550	91.7	Yes	3000K	80

