




Allusion™


Item Number	Item Description	Voltage	Lamp Watts	Wattage Equivalent	Lumens	LPW	CCT	Beam Angle	CRI	Case Quantity
-------------	------------------	---------	------------	--------------------	--------	-----	-----	------------	-----	---------------

**25,000 HOUR ALLUSION LED 15W PARS WITH SMOOTH WARM DIMMING**  
**DIMMABLE 15W PAR38 LAMPS**

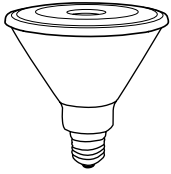


LED15P38DA	15W PAR38— 3000K to 2000K, 25°	120	15	100W	975	65.0	3000K to 2000K	25	80	12
------------	--------------------------------	-----	----	------	-----	------	----------------	----	----	----

**DIMMABLE 15W PAR30 LAMPS**

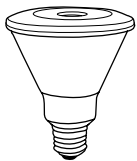


LED15P30DA	15W PAR30—3000K to 2000K, 25°	120	15	100W	950	63.3	3000K to 2000K	25	80	12
------------	-------------------------------	-----	----	------	-----	------	----------------	----	----	----

**25,000 HOUR ALLUSION LED 10W 5/6" RECESSED DOWNLIGHTS WITH SMOOTH WARM DIMMING**

 


LED10DR56DA	10W 5 5/8" Recessed Downlight	120	10	65W	700	70.0	3000K to 2000K	120	80	6
-------------	-------------------------------	-----	----	-----	-----	------	----------------	-----	----	---

**25,000 HOUR ALLUSION LED 10W BR30 WITH SMOOTH WARM DIMMING (REPLACES 65W)**

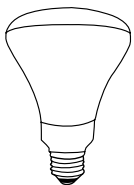

LED10BR30DA	10W BR30	120	10	65W	675	67.5	3000K to 2000K	110	80	12
-------------	----------	-----	----	-----	-----	------	----------------	-----	----	----

**25,000 HOUR ALLUSION LED 9W A LAMPS WITH SMOOTH WARM DIMMING**

 

LED9A19DA	9W A19 A-Lamp	120	9	60W	650	72.2	2700K to 2000K	-	80	12
-----------	---------------	-----	---	-----	-----	------	----------------	---	----	----

**25,000 HOUR ALLUSION LED 5W B11 DECO WITH SMOOTH WARM DIMMING**



LED5E12B11DA	5W B11 Candelabra Blurr Tip	120	5	25W	300	60.0	2400K to 1900K	-	82	12
--------------	-----------------------------	-----	---	-----	-----	------	----------------	---	----	----