
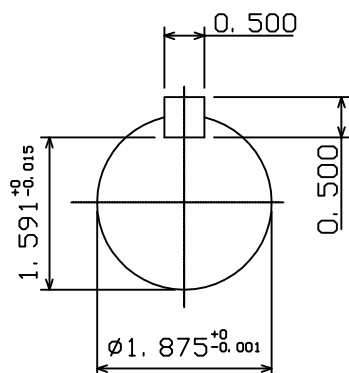


MOTOR TYPE:	AEHH8N
FRAME NO.	286T

Pole	HP	kW	Hz	VOLT	Syn. Speed r/min(rpm)
4	30	22.4	60	230/460	1800
Ins	Rating	Dimension in	Approx Weight	Bearings	
F	CONT.	inches	486 lbs.	DE: 6311ZZ NDE: 6310ZZ	

Totally Enclosed Fan Cooled Type. Squirrel-cage Rotor.

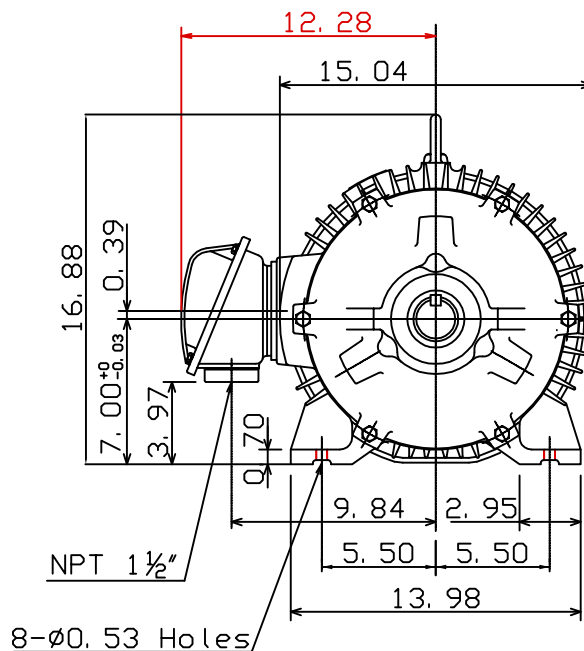

DWG NO.	31057H362300
---------	--------------