

Ty-Rap® High-Performance Stainless Steel Cable Ties

Multiple barb lock design!



Ty-Rap® Multi-Lok Stainless Steel Self-Locking Cable Ties

Fire hazards — corrosive environments — temperature extremes — for many cable bundling applications, plastic ties are simply inadequate—or even dangerous.

That's why we developed stainless steel Multi-Lok Ties. Unaffected by fire, UV or extreme temperatures, corrosion-resistant Multi-Lok Ties provide a safe, strong, worry-free hold.

Quickly and easily applied by hand or with the Thomas & Betts Cable Tie Tensioner or Tensioning Hook, Multi-Lok Ties feature a unique, self-locking, multiple-locking system that holds in excess of 200 lbs.

Nylon II coating is halogen-free and non-toxic black. This weather-resistant coating is unaffected by UV sunlight. This adds resistance to corrosion, chemicals and weathering. Preferred stainless steel strap eliminates sharp edges.

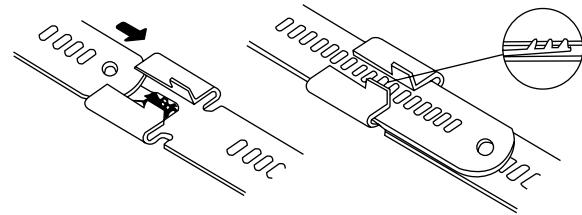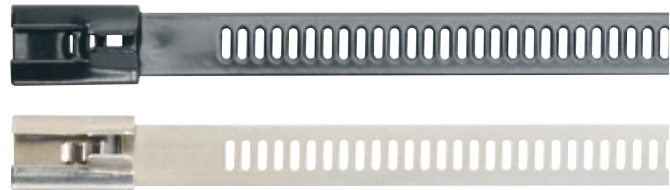

As the free end of the Multi-Lok tie passes through the buckle, three separate teeth (four teeth in the 12mm Multi-Lok) mesh with corresponding slots in the band automatically locking the tie as it is being tensioned. Self-locking Multi-Lok Ties feature an extremely strong, unique multiple locking system.



Type 316 Stainless Steel — Nylon 11 Halogen-Free Coated

CAT. NO.	TENSILE STRENGTH		WIDTH		LENGTH		WEIGHT	
	LBS		IN	MM	IN	MM	LBS	KG
TYS6-280C	250		.276	7	6	150	.66	.30
TYS9-280C	250		.276	7	9	225	.99	.45
TYS12-280C	250		.276	7	12	300	1.32	.60
TYS18-280C	250		.276	7	18	450	1.76	.80
TYS24-280C	250		.276	7	24	610	2.64	1.20
TYS6-470C	250		.472	12	6	150	1.10	.50
TYS9-470C	250		.472	12	9	225	1.65	.75
TYS12-470C	250		.472	12	12	300	2.20	1.00
TYS18-470C	250		.472	12	18	450	2.97	1.35
TYS24-470C	250		.472	12	24	610	4.29	1.95

Packaging Quantity: 100/bag
.010" (.245mm) Thickness

Type 316 Stainless Steel — Uncoated

CAT. NO.	TENSILE STRENGTH		WIDTH		LENGTH		WEIGHT	
	LBS		IN	MM	IN	MM	LBS	KG
TYS6-280	250		.276	7	6	150	.66	.30
TYS9-280	250		.276	7	9	225	.88	.40
TYS12-280	250		.276	7	12	300	1.21	.55
TYS18-280	250		.276	7	18	450	1.98	.90
TYS24-280	250		.276	7	24	610	2.64	1.20
TYS6-470	250		.472	12	6	150	1.10	.50
TYS9-470	250		.472	12	9	225	1.65	.75
TYS12-470	250		.472	12	12	300	2.20	1.00
TYS18-470	250		.472	12	18	450	3.19	1.45
TYS24-470	250		.472	12	24	610	4.29	1.95

Packaging Quantity: 100/bag
.010" (.245mm) Thickness