




MC and AC Cable Fittings

Fits every size of armored cable, metal-clad cable and flexible metal conduit!

Squeeze Connectors — Straight

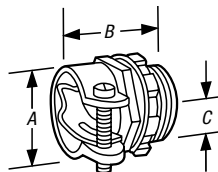

- Malleable iron or steel construction
- Catalog Nos. 252, 253-TB, 254-TB and 255 are steel
- Add "I" suffix for insulated throat

| CAT. NO. | INS. CAT. NO. | CABLE OPENING (IN.) | | TRADE SIZE | K.O. SIZE | DIMENSIONS (IN.) | | |
|-------------|---------------|---------------------|-------|------------|-----------|------------------|--------|-------|
| | | MAX. | MIN. | | | A† | B | C |
| 252*** | — | .531 | .437 | 5/16" | 3/8" | 13/16 | 25/32 | 11/32 |
| 253-TB***† | 253-I-TB***† | .585 | .455 | 3/8" | 1/2" | 31/32 | 113/64 | 5/8 |
| 254-TB | 254-I-TB | .938 | .812 | 1/2" | 1/2" | 17/32 | 13/8 | 13/32 |
| 255 | 255-I | 1.094 | .938 | 3/4" | 3/4" | 11/4 | 117/32 | 7/16 |
| 256 | 256-I | 1.375 | 1.250 | 1" | 1" | 119/32 | 15/8 | 1/2 |
| 257*** | 257-I*** | 1.656 | 1.500 | 11/4" | 11/4" | 17/8 | 123/32 | 17/32 |
| 258*** | 258-I*** | 1.875 | 1.688 | 11/2" | 11/2" | 21/4 | 17/16 | 9/16 |
| 259*** | 259-I*** | 2.500 | 2.313 | 2" | 2" | 231/32 | 25/8 | 11/16 |
| 249*** | 249-I*** | 3.062 | 2.812 | 21/2" | 21/2" | 35/16 | 211/16 | 3/4 |
| 277*** | 277-I*** | 3.563 | 3.312 | 3" | 3" | 313/16 | 27/8 | 3/4 |
| 278-TB***†† | 278-I-TB***†† | 4.370 | 3.200 | 31/2" | 31/2" | 65/8 | 51/4 | 13/16 |
| 281-TB***†† | 281-I-TB***†† | 4.600 | 3.500 | 4" | 4" | 71/4 | 53/4 | 15/8 |

** UL Listed for armored cable only. Fitting material steel.

*** UL Listed for flexible metal conduit only.

† Approximate dimension with screw at minimum height.

†† cULus Certified


.485"–.660" cable opening range for 253-I-TB.

UL File No. E 23018

CSA File No. 2884

Only two screws to tighten!

Squeeze Connectors — 90° Angle

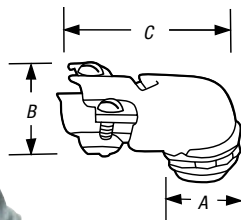

- Cap lifts off simply by loosening screws partway
- 3/8" and 1/2" sizes made of steel
- 3/4" and larger sizes made of malleable iron
- Add "I" suffix for insulated throat

| CAT. NO. | INS. CAT. NO. | CABLE OPENING (IN.) | | TRADE SIZE | K.O. SIZE | DIMENSIONS (IN.) | | |
|-------------|---------------|---------------------|-------|------------|-----------|------------------|--------|--------|
| | | MAX. | MIN. | | | A† | B | C |
| 266-TB | 266-I-TB | .656 | .406 | 3/8" | 1/2" | 11/2 | 113/32 | 17/16 |
| 272** | 272-I** | .812 | .688 | 3/8" | 1/2" | 11/16 | 17/8 | — |
| 268-TB | 268-I-TB | .937 | .813 | 1/2" | 1/2" | 111/16 | 113/16 | 17/8 |
| 279 | 279-I | 1.000 | .875 | 3/4" | 3/4" | 113/16 | 27/16 | 113/16 |
| 270 | 270-I | 1.125 | 1.000 | 3/4" | 3/4" | 17/8 | 17/4 | 113/16 |
| 273-TB | 273-I-TB | 1.406 | 1.187 | 1" | 1" | 25/8 | 27/32 | 27/16 |
| 274*** | 274-I*** | 1.656 | 1.375 | 11/4" | 11/4" | 3 | 3 | 3 |
| 275*** | 275-I*** | 1.875 | 1.625 | 11/2" | 11/2" | 33/8 | 33/16 | 4 |
| 276*** | 276-I*** | 2.500 | 2.125 | 2" | 2" | 41/2 | 313/16 | 47/8 |
| 282-TB***†† | 282-I-TB***†† | 3.100 | 2.520 | 21/2" | 21/2" | 45/16 | 517/16 | 73/16 |
| 283-TB***†† | 283-I-TB***†† | 3.640 | 3.100 | 3" | 3" | 51/16 | 63/16 | 813/16 |
| 284-TB***†† | 284-I-TB***†† | 4.220 | 3.700 | 31/2" | 31/2" | 613/16 | 83/16 | 111/4 |
| 285-TB***†† | 285-I-TB***†† | 4.600 | 4.100 | 4" | 4" | 71/4 | 83/8 | 123/8 |

** UL Listed for armored cable only.

*** UL Listed for flexible metal conduit only.

† Approximate dimension with screw at minimum height.


†† cULus Certified

UL File No. E23018

CSA File No. 2884

Fast and easy installation — simply loosen screws partway to lift off cap!

Squeeze Connectors — 45° Angle

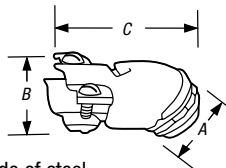

- 3/8" and 1/2" sizes made of steel
- 3/4" size made of malleable iron
- Add "I" suffix for insulated throat

| CAT. NO. | INS. CAT. NO. | CABLE OPENING (IN.) | | TRADE SIZE | K.O. SIZE | DIMENSIONS (IN.) | | |
|----------|---------------|---------------------|-------|------------|-----------|------------------|-------|-------|
| | | MAX. | MIN. | | | A† | B | C |
| 265 | 265-I | .656 | .406 | 3/8" | 1/2" | 117/32 | 15/32 | 17/8 |
| 267 | 267-I | .937 | .813 | 1/2" | 1/2" | 123/32 | 17/2 | 17/4 |
| 269 | 269-I | 1.125 | 1.000 | 3/4" | 3/4" | 2 | 17/32 | 13/16 |

UL File No. E-23018

CSA File No. 2884

UL Listed for armored cable and flexible metal conduit.

† Approximate dimension with screw at minimum height.