

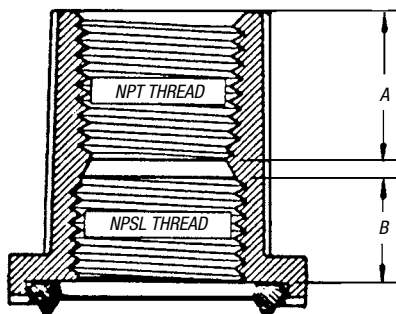
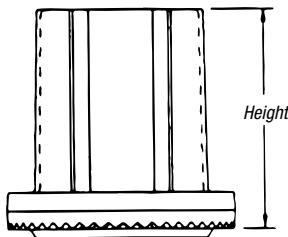


Hubs and Bulkhead Fittings


T&B® Bulkhead Fittings

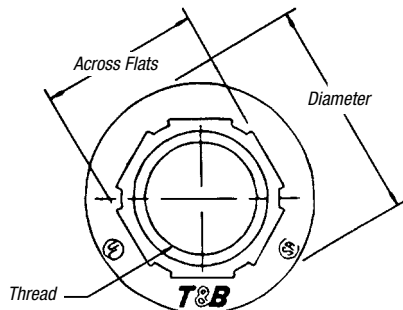

Bulkhead Fitting

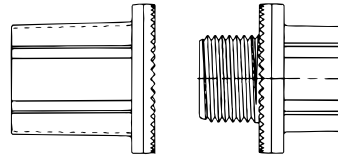


Thru Bulkhead Fitting

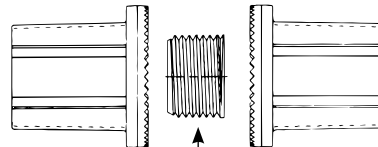

Nipple Nut
Not Included

Thru Bulkhead Hub

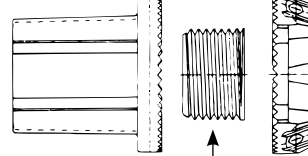

Nipple Nut
Not Included

CAT. NO. TRADE SIZE (IN.)

Bulkhead Fitting

H050BHD	1/2
H075BHD	3/4
H100BHD	1
H125BHD	1 1/4
H150BHD	1 1/2
H200BHD	2
H250BHD	2 1/2
H300BHD	3
H350BHD	3 1/2
H400BHD	4
H500BHD	5
H600BHD	6

Thru Bulkhead Fitting

H050TBF	1/2
H075TBF	3/4
H100TBF	1
H125TBF	1 1/4
H150TBF	1 1/2
H200TBF	2

Thru Bulkhead Hub

H050TBH	1/2
H075TBH	3/4
H100TBH	1
H125TBH	1 1/4
H150TBH	1 1/2
H200TBH	2

TRADE SIZE	THREAD	HEIGHT	DIAMETER	ACROSS FLATS	A (IN.)	B (IN.)
1/2"	1/2"-14"	1 13/32"	1 1/16"	1"	3/4	1/2
3/4"	3/4"-14"	1 15/32"	1 11/16"	1 1/4"	25/32	17/32
1"	1"-11 1/2"	1 11/16"	2"	1 17/32"	29/32	19/32
1 1/4"	1 1/4"-11 1/2"	1 25/32"	2 3/8"	1 27/32"	29/32	21/32
1 1/2"	1 1/2"-11 1/2"	1 13/16"	2 3/4"	1 7/8"	29/32	21/32
2"	2"-11 1/2"	1 27/32"	3 1/4"	2 5/8"	1 5/16	21/32
2 1/2"	2 1/2"-8"	2 3/32"	3 3/4"	3 1/8"	1 1/32	7/8
3"	3"-8"	2 9/16"	4 3/8"	3 23/32"	1 1/16	29/32
3 1/2"	3 1/2"-8"	2 9/16"	5"	4 9/32"	1 3/8	7/8
4"	4"-8"	2 9/16"	5 1/2"	4 27/32"	1 3/8	7/8
5"	5"-8"	2 23/32"	6 3/8"	5 23/32"	1 15/32	7/8
6"	6"-8"	3"	7 1/16"	7 1/32"	1 1/2	31/32

Material — Hub, Body and Locknut: Zinc or copper-free aluminum
 Insulating Throat: Thermoplastic temp. rating — 105° C
 Flammability Rating — 94V-0

Sealing Ring: Nitrile (BUNA "N")
 For Aluminum Bulkheads, add suffix A. UL File No. E-3060
 For Chrome-Plated Bulkheads, add suffix CP. CSA File No. 4484

Meets NEMA sealing requirements for NEMA 3R, 4 & 13 enclosures.