


Couplings and Accessories

Smoothly rounded shoulders protect conductor insulation!

Bushed Elbows

- Non-insulated
- Malleable iron construction

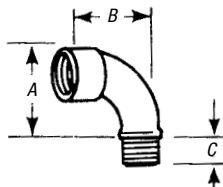


CAT. NO.	SIZE	DIMENSIONS (IN.)		
		A	B	C
460-TB	1/2"	1 1/8	1 13/16	5/8
461TB	3/4"	1 1/2	2 1/4	5/8
462	1"	1 13/16	2 11/16	3/4
463	1 1/4"	2 1/4	3 3/8	3/4

Available with DURA-PLATE® Finish. UL File No. E 23018. CSA File No. 2884

Integral insulation ensures a smooth bushing in every fitting!

Short Elbows — Nylon Insulated

- Malleable iron construction

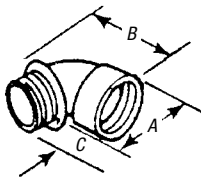


CAT. NO.	SIZE	DIMENSIONS (IN.)		
		A	B	C
4290	1/2"	1 1/32	1 1/4	1/2
4291	3/4"	1 1/16	1 5/16	9/16
4292	1"	1 23/32	1 9/16	1 1/16
4293	1 1/4"	2 1/32	2 1/16	1 3/16
4294	1 1/2"	2 15/32	2 3/16	1 3/16
4295	2"	3	2 5/16	1 3/16

Available with DURA-PLATE® Finish. Not UL or CSA.

For non-insulated applications.

Short Elbows

- Malleable iron construction

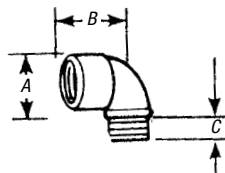


CAT. NO.	SIZE	DIMENSIONS (IN.)		
		A	B	C
4250	1/2"	1 5/16	1 1/4	7/16
4251	3/4"	1 17/32	1 9/16	1/2
4252	1"	1 13/16	1 9/16	5/8
4253	1 1/4"	2 3/32	2 1/16	1 1/16
4254	1 1/2"	2 9/16	2 3/16	1 1/16
4255	2"	3 3/32	2 9/16	1 1/16

Available with DURA-PLATE® Finish. U.L. File #E-23018 CSA File No. 589

Conduit Nipples

- Die-cast zinc
- 1" long

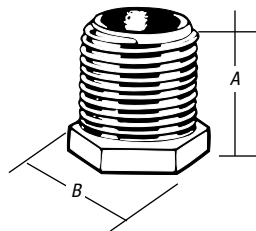


CAT. NO.	SIZE	DIMENSIONS (IN.)	
		A	B
HA-211	1/2"	1"	15/16"
HA-212	3/4"	1"	1 3/16"
HA-213	1"	1"	1 7/16"

UL File No. E-1275 1/2" & 3/4" only

Offset Nipples

- Die-cast zinc

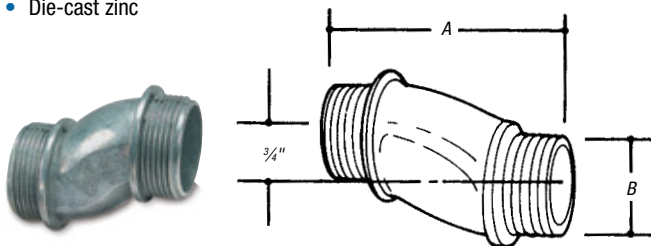

CAT. NO.	SIZE	DIMENSIONS (IN.)	
		A	B
HO-221	1/2"	2.60"	1.00"
HO-222	3/4"	2.62"	1.32"
HO-223	1"	2.68"	1.51"
HO-224	1 1/4"	2.85"	1.85"
HO-225	1 1/2"	2.88"	2.08"
HO-226	2"	3.19"	2.71"

3/4" offset
UL File No. E-1275