

T&B® Fittings

Metal Clad Cable, Armored Cable and Flexible Metal Conduit Fittings

Designed to resist vibration and strain!

TITE-BITE® Connectors — Nylon-Insulated



- Super-fast installation and extreme pull-out resistance due to angled saddle design
- Steel or malleable iron construction
- Tough, insulated lining and Tite-Bite® design make these connectors a "must" when conductors are subject to vibration or strain
- Look for the unique T&B blue color to ensure the highest quality fitting

CAT. NO.	CABLE OPENING (IN.)		TRADE SIZE	K.O. SIZE	DIMENSIONS (IN.)		
	MAX.	MIN.			A†	B	C
2492**#	.500	.370	3/8"	1/2"	1 3/16	1 1/8	7/16
3110-TB**°	.660	.470	3/8"	1/2"	1 1/4	1 1/8	7/8
3112#°	.920	.670	1/2"	3/4"	1 1/4	1 1/8	7/8
3115#	1.125	.906	3/4"	3/4"	1 5/8	1 1/4	1 1/2
3117#	1.468	1.250	1"	1"	2 1/8	1 3/4	1 1/8
3118***	1.750	1.562	1 1/4"	1 1/4"	2 3/8	2	1 1/4
3119***	2.031	1.812	1 1/2"	1 1/2"	3 1/8	2 3/8	1 3/4
3120***	2.500	2.312	2"	2"	3 3/4	2 3/4	1 13/16
3121***	3.062	2.812	2 1/2"	2 1/2"	4 3/8	3 3/4	2 1/4
3122***	3.562	3.312	3"	3"	5	3 3/4	2 1/4
3123***††	4.060	3.620	3 1/2"	3 1/2"	—	—	—
3124***††	4.560	4.120	4"	4"	—	—	—

Material: Steel thru 3/4" trade size.

UL File No. E 23018

CSA File No. 2884

UL Listed for Metal Clad Cable (MCI).

° UL Listed for new Interlocked Armor Ground Type Metal Clad Cable (MCI-A).


* Good for aluminum-sheathed cable.

** UL Listed for Armored Cable and Metal Clad Cable.

*** UL Listed for Flexible Metal Conduit only.

† Approximate dimension with screw at minimum height.

†† CSA not applicable.

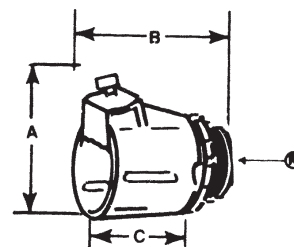

Completely reusable!

TITE-BITE® Connectors



- Easy to install with double-grip saddle
- 3/8" and 1/2" sizes made of formed steel, which produces uniform high quality and a smooth throat to protect conductor insulation
- 3/4" and larger size are malleable iron

CAT. NO.	CABLE OPENING (IN.)		TRADE SIZE	K.O. SIZE	DIMENSIONS (IN.)		
	MAX.	MIN.			A†	B	C
300-TB**°	.660	.470	3/8"	1/2"	1 1/4"	1 1/8	7/16
301-TB**°	.781	.460	3/8"	1/2"	1 1/8	1 1/8	7/8
302-TB#°	.920	.670	1/2"	3/4"	1 1/8	1 1/8	1 1/4
304#	1.093	.906	3/4"	3/4"	1 1/8	1 1/8	1 1/2
306#	1.468	1.250	1"	1"	2 1/8	1 3/4	1 1/8
308***	1.750	1.562	1 1/4"	1 1/4"	2 3/8	2 1/2	1 1/4
310***	2.031	1.812	1 1/2"	1 1/2"	2 3/4	2 3/8	1 3/4
312***	2.500	2.312	2"	2"	3 1/8	2 3/8	1 13/16
314***	3.062	2.812	2 1/2"	2 1/2"	3 3/8	3 3/8	2 1/4
316***	3.562	3.312	3"	3"	4 1/8	3 3/8	2 1/4
318***††	4.060	3.620	3 1/2"	3 1/2"	—	—	—
320***††	4.560	4.120	4"	4"	—	—	—

Material: Steel thru 1/2" trade size.

UL File No. E 23018

CSA File No. 2884

UL Listed for Metal Clad Cable (MCI).

° UL Listed for new Interlocked Armor Ground Type Metal Clad Cable (MCI-A).


* Not UL Listed.

** UL Listed for Armored Cable and Metal Clad Cable.

*** UL Listed for Flexible Metal Conduit only.

† Approximate dimension with screw at minimum height.

†† CSA not applicable.

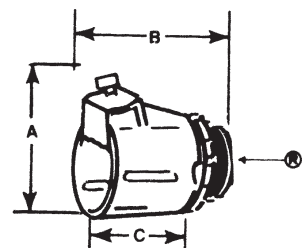

Thomas & Betts

United States
Tel: 901.252.8000
800.816.7809
Fax: 901.252.1354

Technical Services
Tel: 888.862.3289