


Split steel ring with diagonal serrations grips conduit and bites in for positive ground!

### Threadless Connectors — Nylon Insulated



- Makes a permanent connection
- Eliminates need for cutting a thread on conduit
- Insulation helps ensure continuity of service by protecting the conductor at the critical point — the connector bushing
- Malleable iron construction
- Look for the unique T&B blue color, ensuring the highest quality fitting

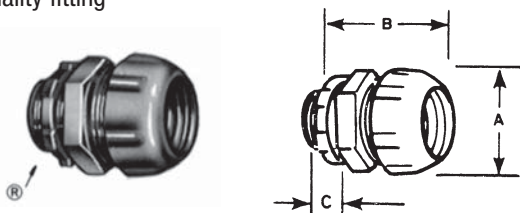

CAT. NO.		CONDUIT SIZE	DIMENSIONS (IN.)		
NYLON INSUL.	NON-INSUL.		A	B	C
8123	8121	½"	1½/₂	1¹/₁₆	1½
8223	8221	¾"	1¹/₂	1¾	1½
8323	8321	1"	1²³/₃₂	2	¾
8423	8421	1¼"	2¾	2¹/₁₆	1¹/₁₆
8523	8521	1½"	2¹¹/₁₆	2¾	¾
8623	8621	2"	3¼	2¹³/₁₆	²⁷/₃₂
8723-TB	8721	2½"	4¾	3¹³/₁₆	1¾
8823	8821	3"	4¾	4	1½
8853	8851	3½"	5½	4¾	1¾
8973	8971	4"	6½	4¾	1¾


Available with DURA-PLATE® Finish. UL File No. E-23018 CSA File No. 2884

Just tighten with a wrench to make a UL Listed and CSA Certified concrete-tight connection!



### Threadless Couplings

- Eliminates need for conduit threading
- Malleable iron construction

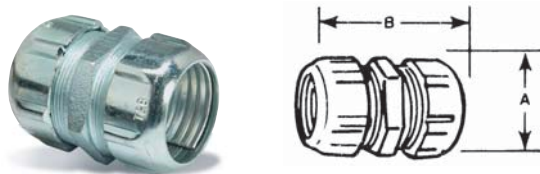

CAT. NO.	SIZE	DIMENSIONS (IN.)	
		A	B
8120	½"	1½/₂	2
8220	¾"	1¹⁹/₃₂	2⁵/₁₆
8320	1"	1¾	2¹¹/₁₆
8420	1¼"	2¾	2¹³/₁₆
8520	1½"	2¾	3⁵/₁₆
8620	2"	3¼	3¹³/₁₆
8720	2½"	3¹³/₁₆	5¾
8820	3"	4¹¹/₁₆	5½
8850	3½"	5¾	5½
8970	4"	5¹¹/₁₆	5½


Available with DURA-PLATE® Finish. UL File No. E-23018 CSA File No. 2884

Ideal for entering enclosure or conduit body at right angles!

### Threadless Short Elbows — Nylon Insulated



- Eliminates need to thread conduit
- As with straight couplings, makes a concrete-tight connection
- Malleable iron construction

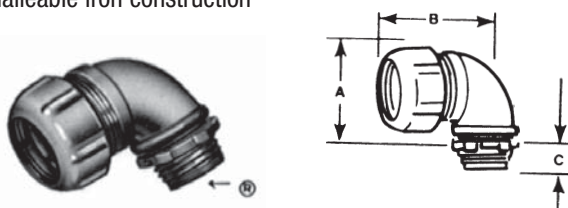

CAT. NO.	SIZE	DIMENSIONS (IN.)		
		A	B	C
8130	½"	1¹¹/₂	1½	½
8131	¾"	1¾	1¾	¾
8132	1"	1¾	1¹⁵/₁₆	¹¹/₁₆

Available with DURA-PLATE® Finish. UL File No. E-23018 CSA File No. 2884