




Actual

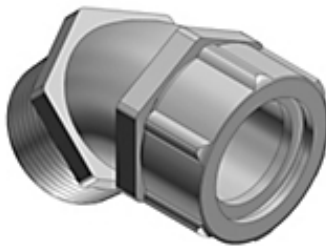

Representative

Catalog Number: 2203
Product ID: 7TBD105260R0004
UPC Number: 78621002203
EAN Number: 05414363183297
Status: A

Liquidtight Strain Relief Cord Connector, 1/2 Inch, 45 Degree Bend, Meets Coast Guard CG293, Cord Range 0.450 to 0.560 Inch, Malleable Iron

- Meets Coast Guard CG293

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Strain Relief Cord Connectors-45 Degree
Special Features	Meets Coast Guard CG293
Application	Suitable for Use In Hazardous Locations Where General Purpose Equipment is Specifically Permitted by NEC 501-4(B).
Standard	UL E13938, CSA
Size	1/2 Inch
Conductor Range	0.450 to 0.560 Inch
Material	Malleable Iron
Color	Metallic

European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1/2 inch
Thread length	14.28mm
Suitable for cable diameter	11.43-14.22mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow
Strain relief	Y

Packaging

Inner Quantity	25
Inner Dimensions (inches)	6x4.5x3
Outer Quantity	50
Outer Dimensions (inches)	8.9x6.7x5.1
Weight Uom	19.52 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet	TDS000048
Support/Tools	Available on Website

Header

3D Model	Available on Website
----------	----------------------