




Actual

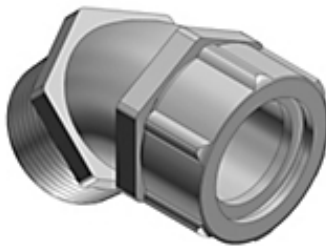

Representative

**Catalog Number:** 2209  
**Product ID:** 7TBD105250R0004  
**UPC Number:** 78621002209  
**EAN Number:** 05414363138860  
**Status:** A

Liquidtight Strain Relief Cord Connector, 3/4 Inch, 45 Degree Bend, Meets Coast Guard CG293, Cord Range 0.500 to 0.625 Inch, Malleable Iron

- Meets Coast Guard CG293

#### North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Strain Relief Cord Connectors-45 Degree
Special Features	Meets Coast Guard CG293
Application	Suitable for Use In Hazardous Locations Where General Purpose Equipment is Specifically Permitted by NEC 501-4(B).
Standard	UL E13938, CSA
Size	3/4 Inch
Conductor Range	0.500 to 0.625 Inch
Material	Malleable Iron
Color	Metallic

#### European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	3/4 inch
Thread length	15.875mm
Suitable for cable diameter	12.7-15.875mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow
Strain relief	Y

#### Packaging

Inner Quantity	10
Inner Dimensions (inches)	5x4.5x3
Outer Quantity	50
Outer Dimensions (inches)	23.8x5.6x4.2
Weight Uom	28.5 lbs. per 100

#### Documents / Support Tools

Technical Drawing / Data Sheet	TDS000048
Support/Tools	Available on Website

#### Header

3D Model	Available on Website
----------	----------------------