




Actual

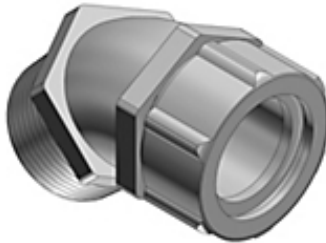

Representative

**Catalog Number:** 2213  
**Product ID:** 7TBD105260R0011  
**UPC Number:** 78621002213  
**EAN Number:** 05414363183440  
**Status:** A

Liquidtight Strain Relief Cord Connector, 1 Inch, 45 Degree Bend, Meets Coast Guard CG293, Cord Range 0.375 to 0.500 Inch, Malleable Iron

- Meets Coast Guard CG293

**North American Specifications (UNSPSC)**

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Strain Relief Cord Connectors-45 Degree
Special Features	Meets Coast Guard CG293
Application	Suitable for Use In Hazardous Locations Where General Purpose Equipment is Specifically Permitted by NEC 501-4(B).
Standard	UL E13938, CSA
Size	1 Inch
Conductor Range	0.375 to 0.500 Inch
Material	Malleable Iron
Color	Metallic

**European Specifications (ETIM)**

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1 inch
Thread length	19.84mm
Suitable for cable diameter	9.525-12.7mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow
Strain relief	Y

**Packaging**

Inner Quantity	5
Inner Dimensions (inches)	5x4.5x3
Outer Quantity	25
Outer Dimensions (inches)	23.9x5.2x3.5
Weight Uom	52 lbs. per 100

**Documents / Support Tools**

Technical Drawing / Data Sheet	TDS000048
Support/Tools	Available on Website

**Header**

3D Model	Available on Website
----------	----------------------