




Actual

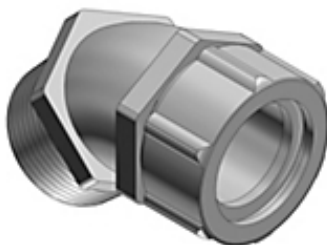

Representative

Catalog Number: 2214
Product ID: 7TBD105260R0012
UPC Number: 78621002214
EAN Number: 05414363183358
Status: A

Liquidtight Strain Relief Cord Connector, 1 Inch, 45 Degree Bend, Meets Coast Guard CG293, Cord Range 0.500 to 0.625 Inch, Malleable Iron

- Meets Coast Guard CG293

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Strain Relief Cord Connectors-45 Degree
Special Features	Meets Coast Guard CG293
Application	Suitable for Use In Hazardous Locations Where General Purpose Equipment is Specifically Permitted by NEC 501-4(B).
Standard	UL E13938, CSA
Size	1 Inch
Conductor Range	0.500 to 0.625 Inch
Material	Malleable Iron
Color	Metallic

European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1 inch
Thread length	19.84mm
Suitable for cable diameter	12.7-15.875mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow
Strain relief	Y

Packaging

Inner Quantity	5
Inner Dimensions (inches)	5.4x3.2x4.69
Outer Quantity	25
Outer Dimensions (inches)	23.8x5.7x4
Weight Uom	45 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet	TDS000048
Catalog Page	Available on Website
Support/Tools	Available on Website

Header

3D Model	Available on Website
----------	----------------------