




Actual

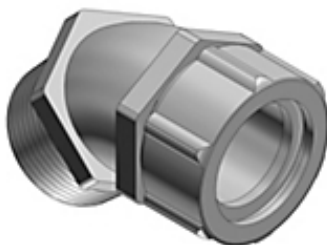

Representative

**Catalog Number:** 2216  
**Product ID:** 7TBD105260R0014  
**UPC Number:** 78621002216  
**EAN Number:** 05414363138884  
**Status:** A

Liquidtight Strain Relief Cord Connector, 1 Inch, 45 Degree Bend, Meets Coast Guard CG293, Cord Range 0.750 to 0.875 Inch, Malleable Iron

- Meets Coast Guard CG293

### North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Strain Relief Cord Connectors-45 Degree
Special Features	Meets Coast Guard CG293
Application	Suitable for Use In Hazardous Locations Where General Purpose Equipment is Specifically Permitted by NEC 501-4(B).
Standard	UL E13938, CSA
Size	1 Inch
Conductor Range	0.750 to 0.875 Inch
Material	Malleable Iron
Color	Metallic

### European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1 inch
Thread length	19.84mm
Suitable for cable diameter	19.05-22.225mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow
Strain relief	Y

### Packaging

Inner Quantity	5
Inner Dimensions (inches)	5x4.5x3
Outer Quantity	25
Outer Dimensions (inches)	5.2x4.7x3.2
Weight Uom	48.81 lbs. per 100

### Documents / Support Tools

Technical Drawing / Data Sheet	TDS000048
Catalog Page	Available on Website
Support/Tools	Available on Website

### Header

3D Model	Available on Website
----------	----------------------