




Actual

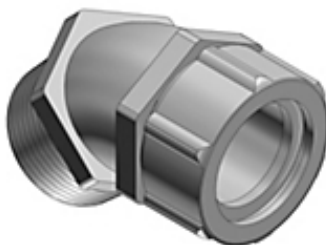

Representative

Catalog Number: 2223
Product ID: 7TBD105260R0021
UPC Number: 78621002223
EAN Number: 05414363183426
Status: A

Liquidtight Strain Relief Cord Connector, 1-1/4 Inch, 45 Degree Bend, Meets Coast Guard CG293, Cord Range 1.375 to 1.485 Inch, Malleable Iron

- Meets Coast Guard CG293

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Strain Relief Cord Connectors-45 Degree
Special Features	Meets Coast Guard CG293
Application	Suitable for Use In Hazardous Locations Where General Purpose Equipment is Specifically Permitted by NEC 501-4(B).
Standard	UL E13938, CSA
Size	1-1/4 Inch
Conductor Range	1.375 to 1.485 Inch
Material	Malleable Iron
Color	Metallic

European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1 1/4 inch
Thread length	20.63mm
Suitable for cable diameter	34.925-37.719mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow
Strain relief	Y

Packaging

Inner Quantity	2
Inner Dimensions (inches)	4x4x3
Outer Quantity	20
Outer Dimensions (inches)	21.5x4.4x3.5
Weight Uom	94 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet	TDS000048
Catalog Page	Available on Website
Support/Tools	Available on Website

Header

3D Model	Available on Website
----------	----------------------