




Actual

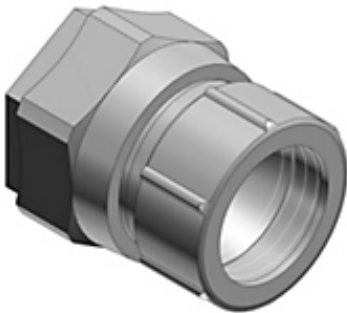

Representative

Catalog Number: 2647
Product ID: 7TAD105150R0006
UPC Number: 78621068785
EAN Number: 05414363190592
Status: A

Chase Liquidtight Cord Connector, 1 Inch, Straight, Steel Body and Gland, Neoprene Bushing, Cord Range 0.625 to 0.750 Inch, Throat Diameter 1 Inch, Metallic

- Meets Coast Guard CG293

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Chase Cord Connectors-Straight
Application	Suitable for Use In Hazardous Locations In Class I, Div. 2; Class II, Div 1 & 2; Class III, Div 1 & 2, Where General Purpose Equipment is Specifically Permitted by NEC 500-2(A).
Standard	UL E13938, CSA 589
Size	1 Inch
Conductor Range	0.625 to 0.750 Inch
Material	Steel
Color	Metallic
Temperature Rating	105 C

European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1 inch
Suitable for cable diameter	15.875-19.05mm
Material	Other
Material quality	Steel
Colour	Natural colour
Model	Straight

Packaging

Inner Quantity	5
Inner Dimensions (inches)	4x4x3
Outer Quantity	25
Outer Dimensions (inches)	21.5x4.37x3.5
Weight Uom	46.38 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet	TDS000049
Support/Tools	Available on Website

Header

3D Model	Available on Website
----------	----------------------