




Actual

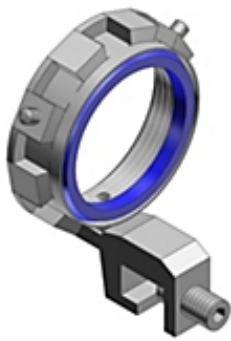

Representative

**Catalog Number:** 3861  
**Product ID:** 7TAD013330R0001  
**UPC Number:** 78621003861  
**EAN Number:** 05415022264937  
**Status:** A

1/2 Inch Threaded Insulated Grounding Bushing, Aluminum, Electro Zinc Plated, Wire Range 8 to 2/0, Thermoplastic Insulator for Use with Rigid/IMC Conduit

- Designed to bush conductors and prevent insulation damage.

### North American Specifications (UNSPSC)

UNSPSC	39121312 Electrical bushing
IGCC	4442 Electrical bushing
Brand Name	T&B
Type	Grounding Bushings & Accessories
Application	For Quick Installation of Bonding Jumper to Multiple Metal Conduits (Rigid and IMC)
Standard	UL E3060, CSA
Size	1/2 Inch
Material	Malleable Iron
Finish	Electro Zinc Plated

### European Specifications (ETIM)

ETIM	EC002357 Support insulator
Length	16.68mm
Outer diameter	28.58mm

### Packaging

Inner Quantity	50
Inner Dimensions (inches)	8x5x4
Outer Quantity	100
Outer Dimensions (inches)	11.2x5.1x8.7
Weight Uom	12.69 lbs. per 100

### Documents / Support Tools

Technical Drawing / Data Sheet US	Available on Website
Instruction Sheet	TA00375-TB2

### Header

3D Model	Available on Website
----------	----------------------