




Actual

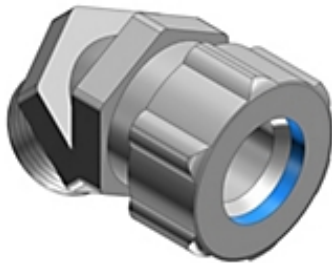

Representative

Location: Newington

ROCKINGHAM ELECTRICAL SUPPLY CO.
 ROCKINGHAM ELECTRICAL SUPPLY
 437 SHATTUCK WAY/PO P1161150

Catalog Number: 4920
Product ID: 7TBD105180R0002
UPC Number: 78621004920
EAN Number: 05414363165422
Status: A

Liquidtight Strain Relief Connector, 1/2 Inch, 45 Degree Bend, Cord Range 0.125 to 0.375 Inch, Throat Diameter 37/64 Inch, Malleable Iron Body, Steel Gland, Plastic Grip, Santropene Bushing

- Reduced overall size, fits into tighter spaces.
- Gland nut designed to restrict cable bending.
- Suitable for Ordinary, Wet or Dry locations.
- Suitable for use in hazardous locations where general purpose equipment is specifically permitted by NEC 501-4(b).

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Cord Connectors-45 Degree
Special Features	Extended Range with Superior Strain Relief
Application	Provide a Means for Passing a Cord Cable Into an Enclosure Through a Bulkhead
Standard	UL E13938, CSA 52391
Size	1/2 Inch
Conductor Range	0.125 to 0.375 Inch
Material	Malleable Iron
Color	Metallic
Environmental Conditions	Ordinary, Wet, or Dry Locations

European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1/2 inch
Thread length	14.28mm
Suitable for cable diameter	3.175-9.525mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow

Packaging

Inner Quantity	25
Inner Dimensions (inches)	6x4.5x3
Outer Quantity	50
Outer Dimensions (inches)	9.7x6.2x3.5
Weight Uom	19.5 lbs. per 100

Documents / Support Tools



Technical Drawing / Data Sheet US

[Available on Website](#)

Header

3D Model

[Available on Website](#)