




Actual

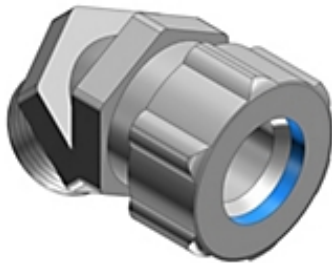

Representative

Catalog Number: 4922
Product ID: 7TBD105190R0030
UPC Number: 78621004922
EAN Number: 05414363165446
Status: Active
Replacement Catalog: 2204

Liquidtight Strain Relief Connector, 1/2 Inch, 45 Degree Bend, Cord Range 0.500 to 0.750 Inch, Throat Diameter 37/64 Inch, Malleable Iron Body, Steel Gland, Plastic Grip, Santropene Bushing

- Reduced overall size, fits into tighter spaces.
- Gland nut designed to restrict cable bending.
- Suitable for Ordinary, Wet or Dry locations.
- Suitable for use in hazardous locations where general purpose equipment is specifically permitted by NEC 501-4(b).

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Brand Name	T&B
Type	Cord Connectors-45 Degree
Special Features	Extended Range with Superior Strain Relief
Application	Provide a Means for Passing a Cord Cable Into an Enclosure Through a Bulkhead
Standard	UL E13938, CSA 52391
Size	1/2 Inch
Conductor Range	0.500 to 0.750 Inch
Material	Malleable Iron
Color	Metallic
Environmental Conditions	Ordinary, Wet, or Dry Locations

European Specifications (ETIM)

ETIM	EC000441 Cable screw gland
Thread type	NPT
Nominal thread size inch/gas pipe thread	1/2 inch
Thread length	14.28mm
Suitable for cable diameter	12.7-19.05mm
Material	Metal
Material quality	Other
Colour	Natural colour
Model	45°-elbow

Packaging

Inner Quantity	10
Inner Dimensions (inches)	5x4.5x3
Outer Quantity	50
Outer Dimensions (inches)	3.6x24.1x5.5
Weight Uom	23.88 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet US	Available on Website
Technical Drawing / Data Sheet Canada	Available on Website

Header

3D Model	Available on Website
----------	----------------------

Thomas & Betts - USA