




Actual

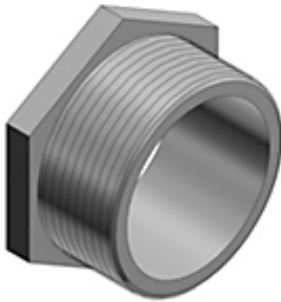

Representative

**Catalog Number:** 851AL  
**Product ID:** 7TAD013130R0018  
**UPC Number:** 78621080173  
**EAN Number:** 05414363146681  
**Status:** A

4 Inch Chase Nipple, Aluminum, Electro Zinc Plated for Use with Rigid/IMC Conduit

**North American Specifications (UNSPSC)**

UNSPSC	39131718 Electrical conduit nipple
IGCC	5753 Electrical conduit nipple
Type	Chase Conduit Nipple
Application	To Effectively Bush Factory or Field-Punched, Cut, or Drilled Holes In Metal Boxes or Enclosures. To Couple Boxes Back-to-Back
Standard	UL E23018, CSA
Material	Aluminum
Finish	Electro Zinc Plated
Trade Size	4 in

**European Specifications (ETIM)**

ETIM	EC001469 Protective hose adapter
With outer thread	Y
Thread size outer thread metric	103
Material housing	Aluminium
Material quality	Other
Surface protection	Untreated
Model	Straight
Material sealing	No sealing

**Packaging**

Inner Quantity	1
Inner Dimensions (inches)	5x4.5x3
Outer Quantity	5
Outer Dimensions (inches)	24.3x5.6x4
Weight Uom	60 lbs. per 100

**Documents / Support Tools**

Technical Drawing / Data Sheet US	Available on Website
-----------------------------------	----------------------

**Header**

3D Model	Available on Website
----------	----------------------