




Actual

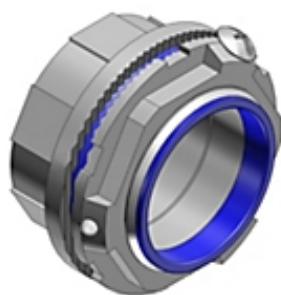

Representative

Catalog Number: H100GRSST
Product ID: 7TBD013740R0002
UPC Number: 78621000280
EAN Number: 05415022258080
Status: A

1 Inch 316 Stainless Steel Grounding Hub, Thermoplastic Insulating Throat, Sealing Ring Nitrile (BUNA-N) for Use with Rigid/IMC Conduit

- Suitable for hazardous locations use in Class I, Division 2; Class II, Division 1&2; Class III, Division 1 & 2 per NEC 501-4(b); 502-4 (a) and 503-3 (a)
- Suitable for hazardous locations use in Class II, Groups E, F, G & Class III locations per CEC 18-202; 18-252; 18-302; 18-352.
- Meets NEMA sealing requirements for NEMA 3R, 4, 4X and 13 enclosures

North American Specifications (UNSPSC)

UNSPSC	39131707 Electrical conduit coupling
IGCC	5548 Electrical conduit coupling
Type	Grounding Hub
Special Features	Hexagonal/Splined Body and Locknut Enable Fast and Easy Installation
Application	For Use with Rigid/IMC Conduit
Standard	UL E23018, CSA
Trade Size	1 in
Outside Diameter	2.00 in
Length	1.81 in
Material	316 Stainless Steel

European Specifications (ETIM)

ETIM	EC001180 Screw connection for protective metallic hose
Nominal size in inch	1 inch
Model	Straight
Revolving thread	N
Connection type screw connection to housing	Thread
Thread type	NPT
Material housing	Stainless steel

Packaging

Inner Quantity	5
Inner Dimensions (inches)	5x4.5x3
Outer Quantity	25
Outer Dimensions (inches)	23.8x5.2x3.5
Weight Uom	55 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet US	Available on Website
Catalog Page	Available on Website