




Actual

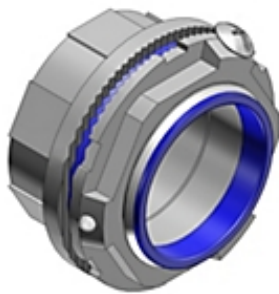

Representative

**Catalog Number:** H125GRSST  
**Product ID:** 7TBD013750R0001  
**UPC Number:** 78621000281  
**Status:** A

1-1/4 Inch Stainless Steel Tan db Hub

- Suitable for hazardous locations use in Class I, Division 2; Class II, Division 1 & 2; Class III, Division 1 & 2 per NEC 501-4(b); 502-4 (a) and 503-3 (a)
- Suitable for hazardous locations use in Class II, Groups E, F, G & Class III locations per CEC 18-202; 18-252; 18-302; 18-352.
- Meets NEMA sealing requirements for NEMA 3R, 4, 4X and 13 enclosures

### North American Specifications (UNSPSC)

UNSPSC	39131707 Electrical conduit coupling
IGCC	5548 Electrical conduit coupling
Type	Grounding Hub
Special Features	Hexagonal/Splined Body and Locknut Enable Fast and Easy Installation
Application	For Use with Rigid/IMC Conduit
Standard	UL E23018, CSA
Trade Size	1-1/4 in
Outside Diameter	2.38 in
Length	1.88 in
Material	316 Stainless Steel

### European Specifications (ETIM)

ETIM	EC001180 Screw connection for protective metallic hose
Nominal size in inch	1 1/4 inch
Model	Straight
Revolving thread	N
Connection type screw connection to housing	Thread
Thread type	NPT
Material housing	Stainless steel

### Packaging

Inner Quantity	5
Inner Dimensions (inches)	6.2x5x3.5
Outer Quantity	15
Outer Dimensions (inches)	11x6.6x5.25
Weight Uom	70.5 lbs. per 100

### Documents / Support Tools

Technical Drawing / Data Sheet US	Available on Website
Catalog Page	Available on Website