




Actual

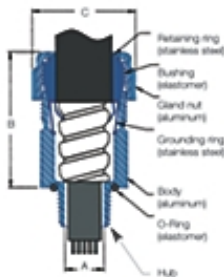

Line Art

Catalog Number: ST350-482S
Product ID: 7TBA051060R0021
UPC Number: 78621063153
EAN Number: 05415022459760
Status: A

Star Teck steel jacketed fitting. Hub size of 3-1/2 inches. Range over jacket from 3.420 - 3.690 inches.

A natural extension of the 10464 Series, the first STAR TECK cable fitting incorporated input from end-users in Canadian industry and was the first teck fitting to use a "pop-on" design requiring no disassembly. Other unique features included a splined gland and gripping features. The original STAR TECK fitting for teck and ACWU cable set the standard for ease of installation, quality engineering and safe, reliable terminations in challenging industrial environments.

- Built-in O-Ring provides 360 degree seal even when enclosure surface is rough or uneven.
- Sharp Biting Teeth provide superior electrical bonding and allow corrosive liquids to drain away quickly.
- Watertight Tapered bushing. Cone shaped to provide a secure, tight fit while eliminating cupping or water in vertical installations.
- Easy to Install in Tight Spaces Low profile gland nut fits tight spaces. Has grooves for screwdriver installation, and flats for a wrench. Durable and reusable with funnel entry for easy cable insertion.

North American Specifications (UNSPSC)

| | |
|----------|--------------------------------|
| UNSPSC | 39121311 Electrical fittings |
| IGCC | 4441 Electrical fittings |
| Type | Teck Cable Fittings |
| Standard | UL E38947, CSA 23086, CSA 4484 |
| Size | 3-1/2 inches |
| Material | Steel |
| Color | Silver |

Packaging

| | |
|----------------|------------------|
| Outer Quantity | 2 |
| Weight Uom | 900 lbs. per 100 |

Documents / Support Tools

| | |
|-----------------------------------|----------------------|
| Technical Drawing / Data Sheet | TDS000037 |
| Technical Drawing / Data Sheet | WSD-001617 |
| Technical Drawing / Data Sheet US | Available on Website |
| Catalog Page | Available on Website |
| Catalog Page | Available on Website |
| Instruction Sheet | TA00904-TB2 |
| Support/Tools | Available on Website |
| Catalog Canada | Available on Website |