




**Catalog Number:** STE050S  
**Product ID:** 7TBA051340R0000  
**UPC Number:** 78621087977  
**EAN Number:** 05415022461602  
**Status:** A

Star Teck steel jacketed fitting. Hub size of 1/2 inch. Range over jacket from 0.600 - 0.985 inch.

The STAR TECK EXTREME fitting was the industry's first range-taking teck fitting. This fitting simplified matching cables to fittings and reduced the number of different size fittings that had to be inventoried. Now one STAR TECK EXTREME fitting could cover the range of three conventional STAR TECK fitting hub sizes. With the STAR TECK EXTREME fitting also came the invention of removable armour stops, another feature that has since become an industry standard.

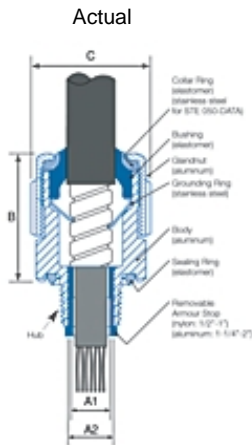

Line Art

- Sharp biting teeth provide superior electrical bonding and allow corrosive liquids to drain away quickly.
- Exclusive power-grip Provides a grip that's high up on the cable - not on the first convolution - so jacket strip length of cable is not critical.
- Power Grip grounding ring is non-magnetic stainless steel. Dual sets of grounding devices ensure 360 degree long-term dependable grounding. It makes immediate contact with the cable during insertion.
- Built-in jacket stripping gauge on each fitting.
- Low profile gland nut fits tight spaces. Has grooves for screwdriver installation, and flats for a wrench. Durable and reusable with funnel entry for easy cable insertion.

### North American Specifications (UNSPSC)

UNSPSC	39121311 Electrical fittings
IGCC	4441 Electrical fittings
Type	Teck Cable Fittings
Standard	UL E38947, CSA 23086, CSA 4484
Size	1/2 inch
Material	Steel
Color	Silver

### Packaging

Outer Quantity	20
Outer Dimensions (inches)	9.2x7.4x3.9
Weight Uom	54.25 lbs. per 100

### Documents / Support Tools

Technical Drawing / Data Sheet	TDS000038
Technical Drawing / Data Sheet US	Available on Website
Catalog Page	Available on Website
Catalog Page	Available on Website
Support/Tools	Available on Website
Catalog Canada	Available on Website