




Catalog Number: TY15X4WHW6
Product ID: 7TAA104070R0001
UPC Number: 78620988471
EAN Number: 05415022260434
Status: A

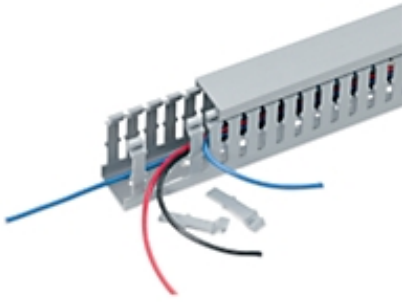

Representative

Wiring Duct Halogen Free Wide Slot 1-1/2 Inch X 4 Inch Modified PPE White

- Higher temperature rating than PVC.
- Wide fingers and slots increase rigidity and enable insertion of bundles.
- V-Shaped slot lead-in enables easier and faster wire installation.
- Rounded edges keep hands and wires free of abrasion.
- Non-slip cover does not slide easily and resists vibration.
- Flush cover attaches flush with sidewall for finished look.
- Dual score lines are designed to yield clean breakoffs at the base of the slot and the duct.
- Versatile North American and DIN Standard mounding holes enables same duct for multiple applications.

North American Specifications (UNSPSC)

| | |
|------------------|---|
| UNSPSC | 39131712 Wiring duct |
| IGCC | 5580 Wiring duct |
| Type | Wide Slot Duct |
| Special Features | Higher temperature rating than PVC. Wide fingers and slots increase rigidity and enable insertion of bundles. V-Shaped slot lead-in enables easier and faster wire installation. Rounded edges keep hands and wires free of abrasion. |
| Width | 1.75 in ; 44.45 mm |
| Depth | 4.37 in ; 111 mm |
| Length | 6 in ; 152.4 mm |
| Slot Style | Wide |
| Mounting Holes | Yes |
| Adhesive Backed | No |
| Material | Modified PPE |
| Color | White |

European Specifications (ETIM)

| | |
|-------------------|--|
| ETIM | EC000012 Slotted cable trunking system |
| Height | 111mm |
| Width | 44.5mm |
| Type of side wall | Slotted |
| Length | 1829mm |
| Halogen free | Y |
| Flexible | N |
| Type of fastening | Adhesive film |
| With cover | N |
| Colour | White |

Packaging

| | |
|---------------------------|--------------------|
| Inner Quantity | 6 |
| Inner Dimensions (inches) | 72x1.5x4 |
| Outer Quantity | 60 |
| Outer Dimensions (inches) | 72x6.5x9 |
| Weight Uom | 46.25 lbs. per 100 |



Documents / Support Tools

Technical Drawing / Data Sheet

WSD-000283