




**Catalog Number:** TY2X3WHW6  
**Product ID:** 7TAA104070R0008  
**UPC Number:** 78620988474  
**Status:** A  
**Replacement Catalog:** 1SL9087A00

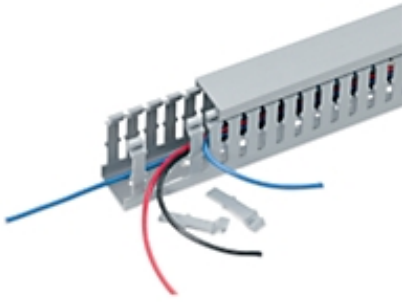

Representative

Wiring Duct Halogen Free Wide Slot 2 Inch X 3 Inch Modified PPE White

- Higher temperature rating than PVC.
- Wide fingers and slots increase rigidity and enable insertion of bundles.
- V-Shaped slot lead-in enables easier and faster wire installation.
- Rounded edges keep hands and wires free of abrasion.
- Non-slip cover does not slide easily and resists vibration.
- Flush cover attaches flush with sidewall for finished look.
- Dual score lines are designed to yield clean breakoffs at the base of the slot and the duct.
- Versatile North American and DIN Standard mounding holes enables same duct for multiple applications.

**North American Specifications (UNSPSC)**

UNSPSC	39131712 Wiring duct
IGCC	5580 Wiring duct
Type	Wide Slot Duct
Special Features	Higher temperature rating than PVC. Wide fingers and slots increase rigidity and enable insertion of bundles. V-Shaped slot lead-in enables easier and faster wire installation. Rounded edges keep hands and wires free of abrasion.
Width	2.25 in ; 57.15 mm
Depth	3.14 in ; 79.76 mm
Length	6 in ; 152.4 mm
Mounting Holes	Yes
Material	Modified PPE
Color	White

**European Specifications (ETIM)**

ETIM	EC000012 Slotted cable trunking system
Height	77.5mm
Width	57.2mm
Type of side wall	Slotted
Length	1829mm
Halogen free	Y
Flexible	N
Type of fastening	Adhesive film
With cover	N
Colour	White

**Packaging**

Inner Quantity	6
Inner Dimensions (inches)	72x3x2
Outer Quantity	60
Outer Dimensions (inches)	73x9.5x6.75
Weight Uom	33.75 lbs. per 100

**Documents / Support Tools**

