


Catalog Number: WMG-PC12
Product ID: 7TAD105280R0000
UPC Number: 78621077009
EAN Number: 05415022459692
Status: A



Actual

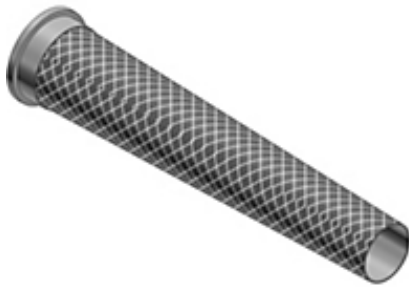

Representative

Stainless Steel Wire Mesh Grip for Use with Liquidtight Cord Fittings, Grip Range 1.000 to 1.125 Inch

- Prevents severe cord bends and pullouts.
- Used with aluminum and/or steel fittings.
- Provides high gripping strength for adequate cable support and strain relief without damage to the cable sheath.

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Wiremesh Grips
Special Features	Prevents Severe Cord Bends and Pullouts
Application	Provides High Gripping Strength for Adequate Cable Support and Strain Relief Without Damage to the Cable Sheath
Standard	UL E13938, CSA
Conductor Range	1.000 to 1.125 Inch
Material	Stainless Steel
Environmental Conditions	Ordinary Locations

Packaging

Inner Quantity	2
Inner Dimensions (inches)	3.5x3x3
Outer Quantity	10
Outer Dimensions (inches)	16.5x5x4.5
Weight Uom	14 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet	TDS000055
Instruction Sheet	TA00083-TB2
Support/Tools	Available on Website

Header

3D Model	Available on Website
----------	----------------------