




**Catalog Number:** WMG-PC6  
**Product ID:** 7TAD105980R0070  
**UPC Number:** 78621077003  
**EAN Number:** 05415022460315  
**Status:** A



Actual

Stainless Steel Wire Mesh Grip for Use with 3/4 Inch Cord Fittings, UL, CSA, Grip Range 0.187 to 0.250 Inch

- Prevents severe cord bends and pullouts.
- Used with aluminum and/or steel fittings.
- Provides high gripping strength for adequate cable support and strain relief without damage to the cable sheath.

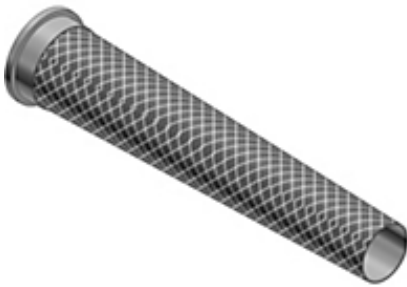

Representative

### North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Type	Wiremesh Grips
Special Features	Prevents Severe Cord Bends and Pullouts
Application	Provides High Gripping Strength for Adequate Cable Support and Strain Relief Without Damage to the Cable Sheath
Standard	UL E13938, CSA
Conductor Range	0.187 to 0.250 Inch
Material	Stainless Steel
Environmental Conditions	Ordinary Locations

### Packaging

Inner Quantity	5
Inner Dimensions (inches)	3.3x2.8x2.3
Outer Quantity	25
Outer Dimensions (inches)	15x3.5x2.6
Weight Uom	6 lbs. per 100

### Documents / Support Tools

Technical Drawing / Data Sheet	TDS000055
Instruction Sheet	TA00083-TB2
Support/Tools	Available on Website

### Header

3D Model	Available on Website
----------	----------------------