




DisplayPort to VGA Active Adapter Video Converter , DP ver 1.2 (M/F), 6 in.

MODEL NUMBER: **P134-06N-VGA-V2**

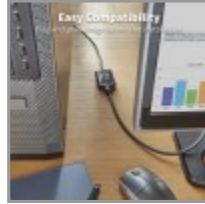

Converts a DisplayPort 1.2 video signal for display on a VGA monitor, projector or television.

Description

The P134-06N-VGA-V2 DisplayPort 1.2 to VGA Active Converter connects a DisplayPort 1.2 computer to the VGA port on a monitor, projector or television. With a male DisplayPort connector and a female HD15 connector, this converter lets you use your existing VGA display instead of buying a new DisplayPort monitor.

Ideal for displaying video on a large monitor or digital sign, this converter supports high-definition video resolutions up to 1920 x 1080 (1080p) and computer video resolutions up to 1920 x 1200. Because it's an active converter, the P134-06N-VGA-V2 converts both Single-Mode and Dual-Mode (DP++) DisplayPort output. It's perfect for use with graphics cards, such as AMD Eyefinity, that do not output DP++ signals.

Plug and play with no software, drivers or power supply needed. Gold-plated connectors and contacts ensure excellent conductivity. Integral strain relief ensures the converter and molded connectors last a long time. The P134-06N-VGA-V2 is backward compatible with previous DisplayPort generations and fits easily in a briefcase, backpack or laptop bag for connecting on the go.

Features

Send High-Definition DisplayPort 1.2 Video Signals to a VGA Display

- Connects DisplayPort 1.2 computer to VGA-enabled monitor, projector or TV
- Ideal for displaying video on large monitor or digital sign
- Female HD15 and male DisplayPort connectors
- Backward compatible with previous DisplayPort generations

Vibrant, Superior Video Quality

- Supports HD video resolutions up to 1920 x 1080 (1080p)

Highlights

- Active converter works with all DisplayPorts
- Supports HD video resolutions up to 1920 x 1080 (1080p)
- Supports computer video resolutions up to 1920 x 1200
- Converts both Single-Mode and Dual-Mode DisplayPort output
- Gold-plated connectors and contacts

Package Includes

- P134-06N-VGA-V2 DisplayPort 1.2 to VGA Active Converter (M/F), 6 in.



- Supports computer video resolutions up to 1920 x 1200
- Converts both Single-Mode and Dual-Mode DisplayPort output
- Works with graphics cards that don't output DP++ signals, such as AMD Eyefinity

Superior Materials for Superior Performance

- Gold-plated connectors and contacts for excellent conductivity
- Integral strain relief for long life
- Plug-and-play—no software, drivers or power supply necessary
- Fits easily into briefcase, backpack or laptop bag

Specifications

OVERVIEW	
UPC Code	037332192042
INPUT	
Cable Length (in.)	6
Cable Length (cm)	15.24
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Weight (kg)	0.04
Shipping Weight (lbs.)	0.08
CONNECTIONS	
Side A - Connector 1	DISPLAYPORT (MALE)
Side B - Connector 1	HD15 (FEMALE)
FEATURES & SPECIFICATIONS	
Technology	VGA/SVGA; DisplayPort
WARRANTY	
Product Warranty Period (Worldwide)	3-year limited warranty



Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

[https://
products/product-certification-agencies](https://products.product-certification-agencies)