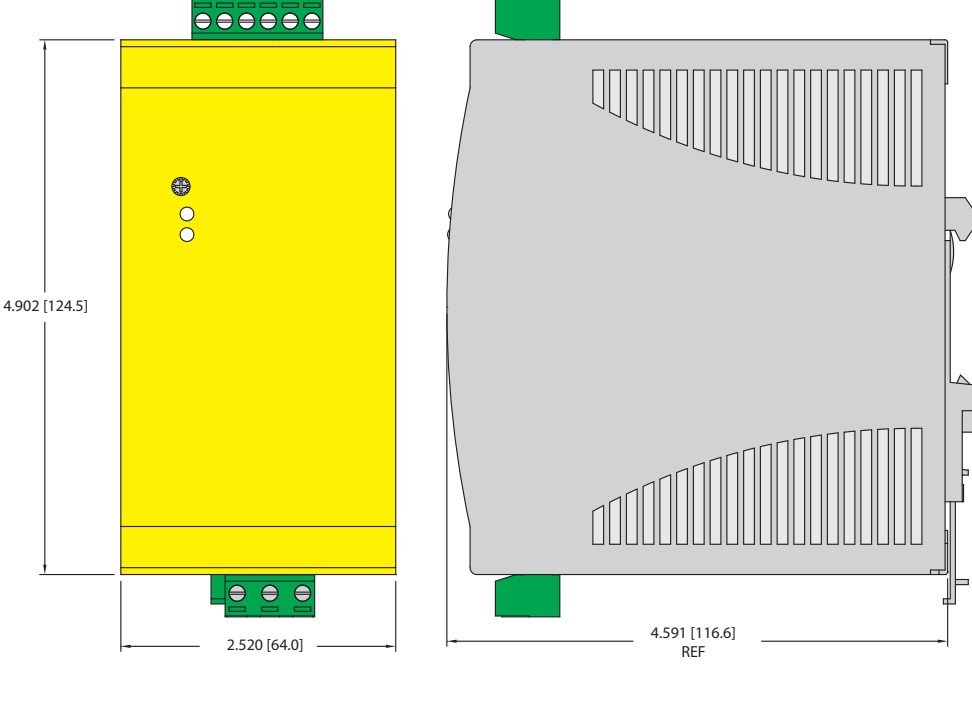


# ACCESSORIES

## In-Cabinet Power Supplies

- 2.5, 5, 10 and 20 Amp Current Available
- Universal Operating Voltage
- Single/parallel Operation
- IP20

Housing Style	Part Number	Protocol
 <p>The drawing shows two views of a power supply unit. The left view is a front view of a yellow rectangular unit with a green terminal block at the top and bottom. It has two indicator lights on the front panel. Dimensions are 4.902 [124.5] in height and 2.520 [64.0] in width. The right view is a side view of a grey unit with cooling fins on both sides and a green terminal block at the top. The width is 4.591 [116.6] REF.</p>	IM82-24-5.0	Power Supply

# DISTRIBUTED I/O SALES GUIDE



Pictures represent a sampling of housings

Connector/Gland Material	Housing Material	Certifications	Notes
Nylon	Aluminum	UL, CE	24 VDC, 5.0A supply, IP20



Accessories