



12-Pin *multifast*® Cordsets, DC Color Code, Standard Wiring, M23 Thread

- Right Angle Female Connector
- For *euromast*® Junction Boxes and multi-conductor Applications
- IEC IP 67 Protection
- 300 V, 6.0 A

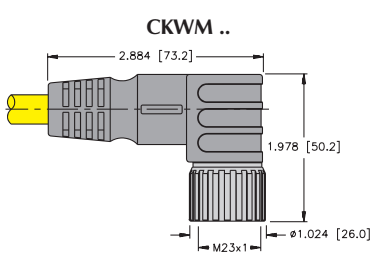

Housing Style	Part Number	Cable	Ports, App.	Features	Pinout
	CKWM 12-7-*	ITC/PLTC PVC Yellow 7x18 AWG 105° C 7.9 mm OD Cable #RF50637-*M†	4 port, 1 Signal per port	<i>flexlife</i>	1. BN 3. BU 4. WH 6. GN 7. YE 8. GY 12. GN/YE
	CKWM 12-7-*/S90	AWM PUR Yellow 7x18 AWG 105° C 7.2 mm OD Cable #RF50676-*M†		<i>Cut/Abrasion Immune</i>	
	CKWM 12-9-*	ITC/PLTC PVC Yellow 9x18 AWG 105° C 10 mm OD Cable #RF50636-*M†	6 port, 1 Signal per port	<i>flexlife</i>	1. BN 3. BU 4. WH 6. GN 7. YE 8. GY 9. PK 10. RD 12. GN/YE
	CKWM 12-9-*/S90	AWM PUR Yellow 9x18 AWG 105° C 10.0 mm OD Cable #RF50677-*M†		<i>Cut/Abrasion Immune</i>	
	CKWM 12-11-*	ITC/PLTC PVC Yellow 11x18 AWG 105° C 10 mm OD Cable #RF51088-*M†	8 port, 1 Signal per port	<i>flexlife</i> ®	1. BN 3. BU 4. WH 5. GN 6. YE 7. GY 8. PK 9. RD 10. BK 11. VT 12. GN/YE
	CKWM 12-11-*/S90	AWM PUR Yellow 11x18 AWG 105° C 10 mm OD Cable #RF50678-*M†		<i>Cut/Abrasion Immune</i>	
	CKWM 12-12-*/S101	AWM TPE Yellow 12x18 AWG 105° C 10.4 mm OD Cable #RF50915-*M†	8 port, 1 Signal per port	<i>flexlife-10, High Flex - Over 10 million cycles</i>	1. BN 2. BU 3. WH 4. GN/YE 5. OG 6. YE 7. GY 8. PK 9. RD 10. BN/WH 11. BU/WH 12. GN/WH
	CKWM 12-12-*/S817	AWM PVC Yellow 12x18 AWG 105° C 10.0 mm OD Cable #RF50606-*M†		<i>flexlife</i>	

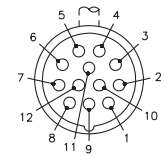

Cordsets


\* Length in meters.  
Standard cable lengths are 5 and 10 meters. Consult factory for other lengths.  
Standard coupling nut material is nickel plated brass.. "CKWM.."; "CKWMV.." indicates stainless steel coupling nut.  
† See Section N for *reelfast*® cable information.

**12-Pin *multifast*® Cordsets, DC Color Code, Standard Wiring, M23 Thread**

- Straight Male Connector
- For *euromast*® Junction Boxes and multi-conductor Applications
- IEC IP 67 Protection
- 300 V, 6.0 A



Housing Style	Part Number	Cable	Ports, App.	Features	Pinout
	CSM 12-7-*	ITC/PLTC PVC Yellow 7x18 AWG 105° C 7.9 mm OD Cable #RF50637-*M†	4 port, 1 Signal per port	<i>flexlife</i>	1. BN 3. BU 4. WH 6. GN 7. YE 8. GY 12. GN/YE
	CSM 12-7-*/S90	AWM PUR Yellow 7x18 AWG 105° C 7.2 mm OD Cable #RF50676-*M†		<i>Cut/Abrasion Immune</i>	
	CSM 12-9-*	ITC/PLTC PVC Yellow 9x18 AWG 105° C 10 mm OD Cable #RF50636-*M†	6 port, 1 Signal per port	<i>flexlife</i>	1. BN 3. BU 4. WH 6. GN 7. YE 8. GY 9. PK 10. RD 12. GN/YE
	CSM 12-9-*/S90	AWM PUR Yellow 9x18 AWG 105° C 10.0 mm OD Cable #RF50677-*M†		<i>Cut/Abrasion Immune</i>	
	CSM 12-11-*	ITC/PLTC PVC Yellow 11x18 AWG 105° C 10 mm OD Cable #RF51088-*M†	8 port, 1 Signal per port	<i>flexlife</i> ®	1. BN 3. BU 4. WH 5. GN 6. YE 7. GY 8. PK 9. RD 10. BK 11. VT 12. GN/YE
	CSM 12-11-*/S90	AWM PUR Yellow 11x18 AWG 105° C 10 mm OD Cable #RF50678-*M†		<i>Cut/Abrasion Immune</i>	
	CSM 12-12-*/S101	AWM TPE Yellow 12x18 AWG 105° C 10.4 mm OD Cable #RF50915-*M†	8 port, 1 Signal per port	<i>flexlife-10, High Flex - Over 10 million cycles</i>	1. BN 2. BU 3. WH 4. GN/YE 5. OG 6. YE 7. GY 8. PK 9. RD 10. BN/WH 11. BU/WH 12. GN/WH
	CSM 12-12-*/S817	AWM PVC Yellow 12x18 AWG 105° C 10.0 mm OD Cable #RF50606-*M†		<i>flexlife</i>	

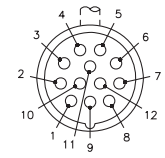

Cordsets

\* Length in meters.  
Standard cable lengths are 5 and 10 meters. Consult factory for other lengths.  
Standard coupling nut material is nickel plated brass.. "CSM.."; "CSMV.." indicates stainless steel coupling nut.  
† See Section N for *reelfast*® cable information.