
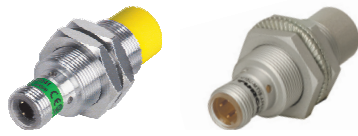
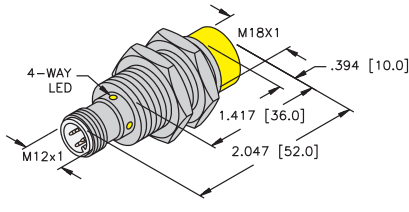


Inductive Sensors

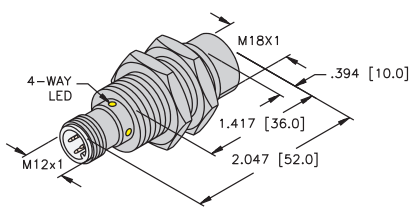

Housing Style	Part Number	ID Number	Features	Sensing Range (mm)	Output	
18 mm - Nonembeddable, eurofast® Connection 	Ni 8-M18-AD4X-H1141	T4414700		8	2-Wire DC	
	Ni 8-M18-AD4X-H1144	T4411288		8		
	Ni 14-M18-AD4X-H1141	T4417241	Ext. Range	14		
	Ni 14-M18-AD4X-H1144	T4417290	Ext. Range	14		
	Ni 8-M18-AN6X-H1141	T4614800		8	3-Wire DC NPN	
	Ni 10-M18-AN6X-H1141	T4614892		10		
	Ni 12U-EM18-AN6X-H1141	M1645350	Uprox	12		
	Ni 12U-M18-AN6X-H1141	M1645150	Uprox	12		
	Ni 14-M18-AN6X-H1141	T4611410	Ext. Range	14		
	Ni 15U-EM18-AN6X-H1141	M1635336	Uprox+ Stainless steel	15		
	Ni 15U-M18-AN6X-H1141	M1635335	Uprox+	15		
	Ni 8-M18-AP6X-H1141	T4614700		8	3-Wire DC PNP	
	Ni 10-M18-AP6X-H1141	T4641291		10		
	Ni 12U-EM18-AP6X-H1141	M1645340	Uprox	12		
	Ni 12U-EM18-AP6X2-H1141	M1645345	Uprox	12		
	Ni 12U-M18-AP6X-H1141	M1645140	Uprox	12		
	Ni 12U-M18-AP6X2-H1141	M1645145	Uprox	12		
	Ni 14-M18-AP6X-H1141	T4611400	Ext. Range	14		
	Ni 15U-EM18-AP6X-H1141	M1635332	Uprox+ Stainless steel	15		
	Ni 15U-M18-AP6X-H1141	M1635331	Uprox+	15		
	Ni 8-M18-VN4X-H1141	T1571900	Comp. Outputs	8	4-Wire DC NPN	
	Ni 14-M18-VN4X-H1141	T4590603	Ext. Range	14		
	Ni 8-M18-VP4X-H1141	T1561900	Comp. Outputs	8	4-Wire DC PNP	
	Ni 14-M18-VP4X-H1141	T4590602	Ext. Range	14		
	Ni 10-M18-Y1X-H1141	M4015300		10	2-Wire NAMUR	
	18 mm - Nonembeddable, eurofast Connection, PTFE Coated 	Ni 12U-MT18-AN6X-H1141	M1645250	Uprox	12	3-Wire DC NPN
		Ni 15U-MT18-AN6X-H1141	M1635337	Uprox+ PTFE	15	
		Ni 15U-MT18-AN6X-H1141/S1589	M16353370	Uprox+ PTFE, weldguard	15	
Ni 12U-MT18-AP6X-H1141		M1645240	Uprox	12	3-Wire DC PNP	
Ni 12U-MT18-AP6X2-H1141		M1645245	Uprox	12		
Ni 12U-MT18H-AP6X-H1141/S1589		M1645292	weldguard® Uprox	12		
Ni 12U-MT18H-AP6X2-H1141/S1589		M1645293	weldguard® Uprox	12		
Ni 15U-MT18-AP6X-H1141		M1635333	Uprox+ PTFE	15		
Ni 15U-MT18-AP6X-H1141/S1589		M1635333-1	Uprox+ PTFE, weldguard	15		

For detailed sensor specifications see Section M.
Normally Closed versions available upon request, consult factory.