

# S5-M




Three pole, three level, logic wiring  
Integrated clip and marking label

16 A 400 V


Socket for MRC, 11-Pin Plug-In Relay Types  
C5-A20, C5-A30, C5-G30, C5-X10, C5-M10,  
C5-M20, C5-R20

- DIN rail or panel mountable
- Removable label
- EN/DIN and sequential numbering

## Wiring Diagram

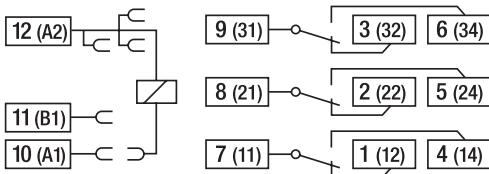

## Dimensions - mm

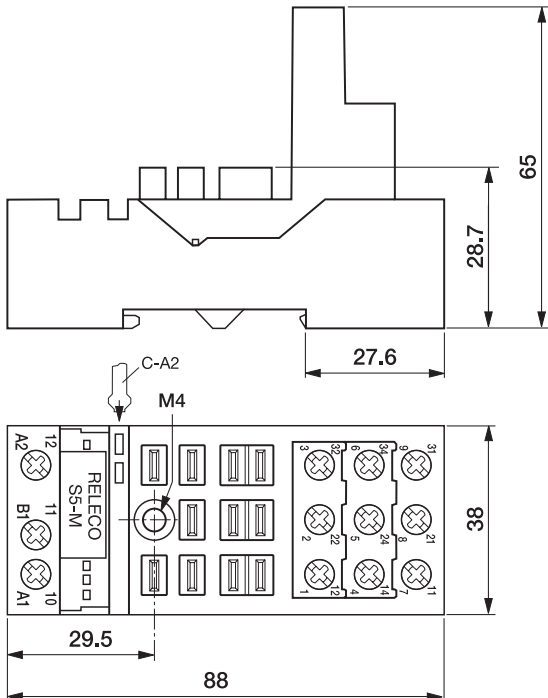

## Specifications

Nominal Load: 16 A/400 V

### Insulation:

Dielectric strength, 1 minute	
Between contacts and coil	4 KV
Between all terminals and rail DIN	4 KV
Between adjacent poles	4 KV

### Wire In-Lets Capacity:

Solid wire	6 mm <sup>2</sup> or 2 x 2.5 mm <sup>2</sup>
Multi-core	10, 16 AWG
Ferrule tip terminals	4 mm <sup>2</sup>
Max. screw torque	1.2 Nm
Screw dimensions	M3.5 Pozi
Integrated hold-down clip	
Removable marking label	

